

## Single Pole Devices and Temporary Power

400A, 600V AC/DC

### Female Plug

#### Features

- Extra Long non-conductive inner sleeve
- Turn and Lock Symbol aids in the mating of devices
- Easily Identifiable Cable with cut off points for secure fit

#### Ordering Information

Description	Device Color	UPC Number	Catalog Number
400A, thermoplastic elastomer, cable size 2/0 - 4/0 AWG	Black	783585113722	HBL400FBK

#### Listings

UL and cUL Listed  
UL Enclosure Types 3R, 4X, 12  
National Electric Code (NEC), ANSI/NFPA 70

#### Specifications

Base Compound	Thermoplastic Elastomer
Contact Material	Brass
Retaining Screw Material	Nylon

#### Performance

##### Electrical

Amperage Rating	400A Maximum
Voltage Rating	600V AC/DC Maximum


##### Mechanical

Product Identification	Ratings are a permanent part of device
Terminal Accommodation	2/0 to 4/0 AWG

##### Environmental

Flammability	HB per UL94 or CSA 22.2. 0.17
--------------	-------------------------------

# HUBBELL

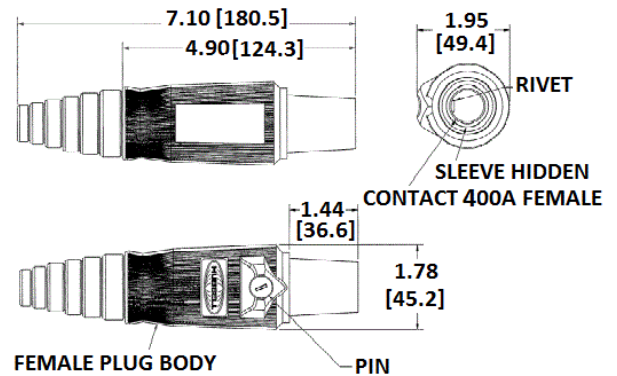

#### Online Resources

Customer Sales Drawings  
eCatalog  
Installation Instructions

Dimensions in Inches (mm)

Specifications subject to change without notice.

