

Xcelerator Jacks

HUBBELL

Xcelerator USOC Jack

Features

- RJ-25 USOC (RJ-25) Jack
- Exclusive 1-Punch Termination Reduces Termination Time by 75%
- Mating Cycles Exceed Industry Standard by Four Times
- Bulk Packaging Reduces Excess Waste on the Job

Ordering Information

| Description | Color | Catalog No. | UPC |
|----------------------|-------|-------------|--------------|
| Xcelerator USOC Jack | Blue | HXJUB | 662620824703 |

Listings

6-Position USOC Compliant
Mechanical TIA-568-C.2
UL Listed 1863
CSA Certified
RoHS Compliant

Specifications

| | |
|--------------|--|
| Nose Contact | Beryllium copper with precious metal plating over nickel under plating |
| IDC Contact | Phosphor bronze with 100 micro-inch tin lead 60/40 plating over nickel under plating |
| Housing | High impact thermoplastic (UL 94 V-0) |

Performance

Electrical


6-Position USOC Compliant

Mechanical

Nose Contact Mating Cycles: 2000
IDC Contact Termination: 10x
Keystone Latching Force: 25 lbs.
Contact performance confirmed over the full range of ISO/FCC compliant plug

Applications

Phone
DSL

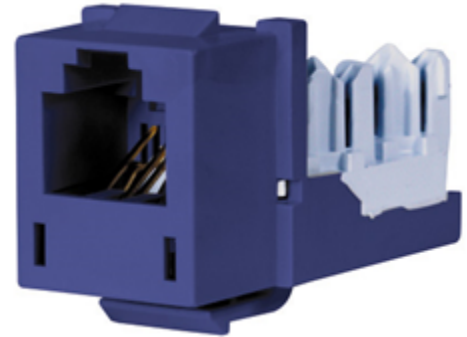

Accessories

| | |
|------------------|---------|
| 1-Punch Tool | TX4P |
| Dust Cover | HXJDC25 |
| Termination Puck | HXTP25 |

Online Resources

eCatalog