

Xcelerator Jacks

HUBBELL

Xcelerator USOC Jack

Features

- RJ-25 USOC (RJ-25) Jack
- Exclusive 1-Punch Termination Reduces Termination Time by 75%
- Mating Cycles Exceed Industry Standard by Four Times
- Bulk Packaging Reduces Excess Waste on the Job

Ordering Information

Description	Color	Catalog No.	UPC
Xcelerator USOC Jack	Orange	HXJUOR	662620824734

Listings

6-Position USOC Compliant
Mechanical TIA-568-C.2
UL Listed 1863
CSA Certified
RoHS Compliant

Specifications

Nose Contact	Beryllium copper with precious metal plating over nickel under plating
IDC Contact	Phosphor bronze with 100 micro-inch tin lead 60/40 plating over nickel under plating
Housing	High impact thermoplastic (UL 94 V-0)

Performance

Electrical


6-Position USOC Compliant

Mechanical

Nose Contact Mating Cycles: 2000
IDC Contact Termination: 10x
Keystone Latching Force: 25 lbs.
Contact performance confirmed over the full range of ISO/FCC compliant plug

Applications

Phone
DSL

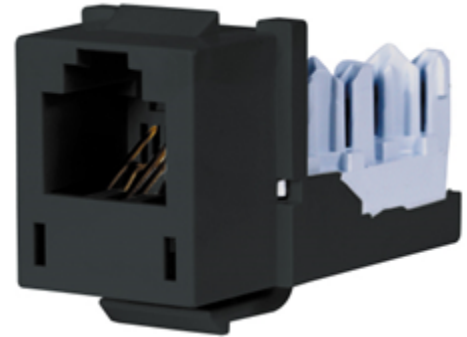

Accessories

1-Punch Tool	TX4P
Dust Cover	HXJDC25
Termination Puck	HXTP25

Online Resources

eCatalog