 


# TradeSelect® Residential Grade 30A 125/250V, 3-Pole 4-Wire Grounding Surface Mount Receptacle

# HUBBELL®

## Features

- Flush Mount for 1- or 2-Gang Box
- Residential Range and Dryer Receptacle



## Ordering Information

Description	Color	UPC	Catalog Number
TradeSelect Flush Mount Receptacle for 1- or 2-Gang Box 30A 125/250V 3 Pole, 4 Wire with Ground	Black	883778100819	RR430

## Listings



UL Listed

## Specifications

Color	Black
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Material - Mounting Hardware	Screw Mounting
Number Of Poles	3-Pole
Series	Heavy Duty
Type	Single Receptacle

## Electrical

Amperage Rating	30 A
Connectivity	Pressure Terminal Screws
Current / Amperage Rating	30 A
Current Rating	30 A
Phase	Single Phase
Voltage Rating	125/250 V
Voltage Rating Description	125/250 V
Wattage	7500
Number Of Wires	4-Wire
Wire Size	#10 AWG

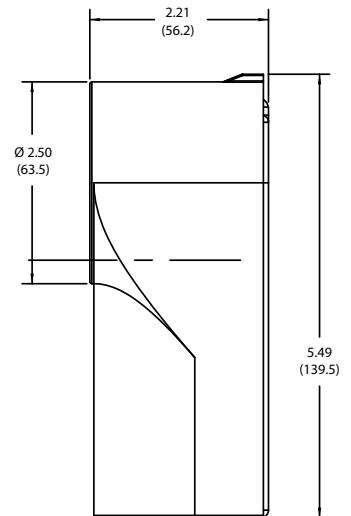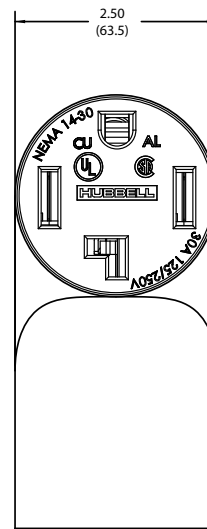

## Links

- [Customer Drawings](#)
- [Installation Instructions](#)
- [Media](#)

