

## Switches, Four Way

15A, 120V AC

# Residential Toggle Switch

### Features

- Elongated strap for easier wall box mounting
- Tough thermoplastic with ultrasonically welded cover and base

### Ordering Information

Description	Color	UPC Number	Catalog Number
Toggle, Self-Grounding, Push & Side Wire	Ivory	883778101335	RS415I

### Listings

UL Listed E3896  
CSA Certified

### Specifications

Top Material	Plastic
Base Material	Plastic
Toggle Material	Plastic
Contacts	Silver Alloy
Terminal Screws	Brass
Auto Grounding Mounting Bridge	Zinc-Plated Steel
Ground Screw	Steel (Green)
Mounting Screw	Zinc-Plated Steel


### Performance

Electrical	
Dielectric Voltage	Withstands 1500V AC minimum for 1 minute
Max. Continuous Current	15A
Max. Working Voltage	120V AC
Overload	Minimum 1.5 times rating
Temperature Rise	30°C maximum at rated current

### Environmental

Flammability	UL 94 V-2
Operating Temperature	Maximum continuous 60°C; minimum -20°C (w/o impact)

# HUBBELL

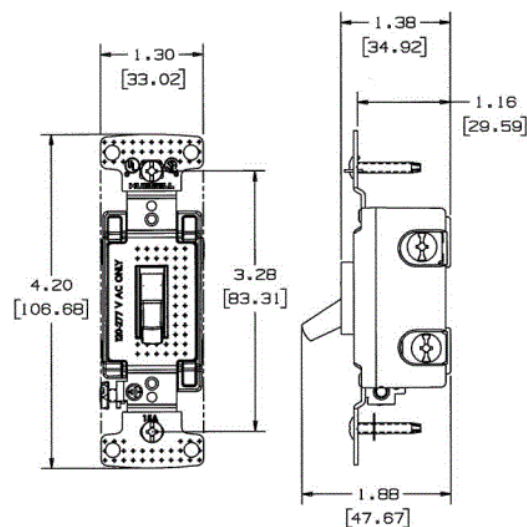

### Online Resources

Customer Sales Drawing  
eCatalog  
Installation Instructions

Dimensions in Inches (mm)

Specifications subject to change without notice.

