

Wall Plates  
 Weatherproof Plates  
 Non-Metallic, Extra Duty, Recessed Cover


# HUBBELL

**Features**

- NEMA Type 3R, NEC compliant
- Meets extra-duty rating
- Recessed low profile
- Mounts horizontally or vertically

**Ordering Information**

Description	Device Color	UPC	Catalog Number
Weatherproof Non-Metallic, Extra Duty, Recessed Cover	Clear/Bronze	883778309717	RW5420CZ

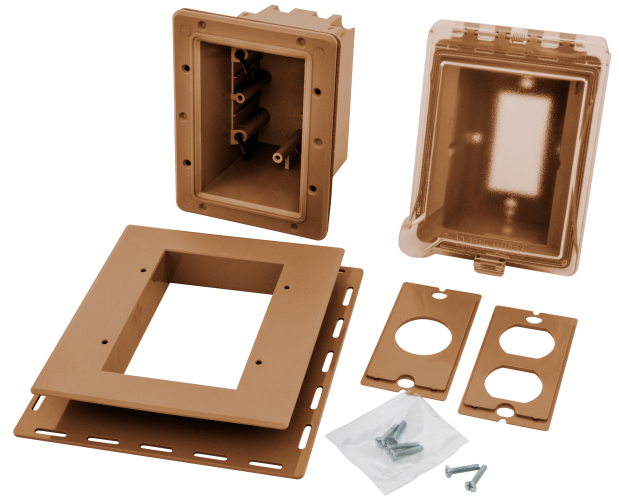

**Listings**


cULus Listed  
 UL 94

**Specifications**

Cover	Clear Polycarbonate
Base	Polycarbonate
Gasket	Silicon

**Performance**

Environmental	
Weatherproof	3R Rated
Flammability	UL V0
Operating Temperatures	Maximum continuous 60°C minimum -40°C (without impact)

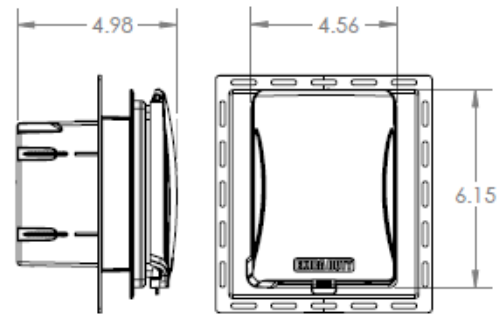

Dimensions in Inches (mm)

Specifications subject to change without notice.

