

## Features

- Durable, Corrosion Resistant Cast Aluminum Construction
- UL Type 1
- Multi-Position Guide Arm can be mounted in two different positions
- Positive Latch mechanism automatically maintains desired cord length
- Ratchet Lock can be disengaged in field for constant tension applications



## Ordering Information

Description	UPC	Catalog Number
Yellow Industrial Reel, UL Type 1, 35 Ft, #14/4 SJO, 15 A, 250 VAC	783585585284	HBLI35144Y

## Listings

cULus Listed

## Specifications



Spool	Aluminum
Guide Frame	Thermoplastic
Cord	Copper
Internal Terminals	Copper Alloy
Ball Stopper	Thermoplastic
Fitting	Aluminum

## Performance

Electrical	
Amperage	15 A
Max. Working Voltage	250V AC
Number of Wires	4-Wire

## Environmental

Moisture Resistance	Dry, Indoor, Non-Hazardous Locations - UL Type 1
---------------------	--

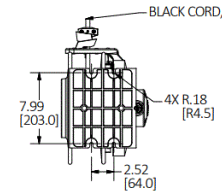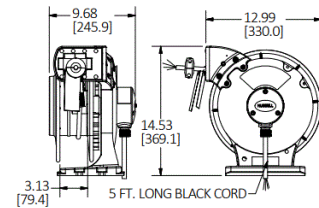

## Complementary Products

Pivot Base	HBLI340PB
Mounting Bracket	HBLIMB
Ball Stop	HBLI16BS

## Online Resources

Customer Sales Drawing  
eCatalog  
Installation Instructions