


## Blued-Steel™ Fish Tapes

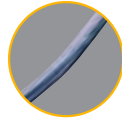


- Laser etched in 12" increments to provide instant conduit length
- High column strength for longer runs
- Non-oily finish resists rust

Length (ft.)	Width & Thickness	Case Diameter	End Type	Tuff-Grip™ Pro	Thumb-Winder™	Replacement Tapes (No Case)
25	1/8 in. x .045 in.	7 in.	Formed hook	—	<b>31-012</b>	—
50	1/8 in. x .045 in.	7 in.	Formed hook	—	<b>31-010</b>	—
50	1/8 in. x .060 in.	9 in.	Formed hook	<b>31-033</b>	—	<b>31-004</b>
60	1/8 in. x .060 in.	12 in.	Formed hook	<b>31-055</b>	—	<b>31-035</b>
120	1/8 in. x .060 in.	12 in.	Formed hook	<b>31-056</b>	—	<b>31-036</b>
240	1/8 in. x .060 in.	12 in.	Formed hook	<b>31-057</b>	—	<b>31-038</b>
50	1/4 in. x .060 in.	12 in.	Formed hook	<b>31-059</b>	—	<b>31-051</b>
100	1/4 in. x .060 in.	12 in.	Formed hook	<b>31-058</b>	—	<b>31-050</b>
200	1/4 in. x .060 in.	None	Formed hook	—	—	<b>31-052</b>
400	1/4 in. x .060 in.	None	Formed hook	—	—	<b>31-2128</b>
—	1/4 in. x .060 in.	None	Formed hook	—	—	<b>31-2982*</b>

\*Bulk roll 750 lbs. (approximately 12,000 ft.)

## Stainless Steel Fish Tapes

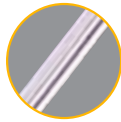

- Laser etched in 12" increments to provide instant conduit length
- Tape will not rust or corrode in humid environments
- Stainless steel design provides a smooth pay-out

Length (ft.)	Width & Thickness	Case Diameter	End Type	Tuff-Grip™ Pro	Replacement Tapes (No Case)
120	1/8 in. x .060 in.	12 in.	Formed hook	<b>31-066</b>	—
240	1/8 in. x .060 in.	12 in.	Formed hook	<b>31-067</b>	<b>31-074</b>

## S-Class® Fiberglass Fish Tapes



- Superior tip design provides optimal strength and reduces wire stress during pulling
- Smooth nylon jacket provides great handling around bends

Length (ft.)	Width & Thickness	Case Diameter	End Type	Tuff-Grip™ Pro	Replacement Tapes (No Case)
50	3/16 in. diameter	12 in.	Non-Conductive Eyelet	<b>31-086</b>	<b>31-200</b>
100	3/16 in. diameter	12 in.	Non-Conductive Eyelet	<b>31-087</b>	<b>31-201</b>
200	3/16 in. diameter	16 in.	Non-Conductive Eyelet	<b>31-088</b>	<b>31-202</b>