


Terminal Arrangement

Terminal Arrangement (Bottom View)


Non-illuminated

NC main contacts only

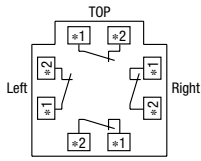


1NC: Terminals on right
2NC: Terminals on right and left
3NC: Terminals on right, left, and top

With 1NO monitor contact

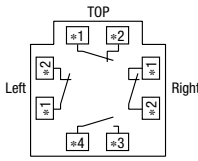


1NC: Terminals on top
2NC: Terminals on right and left

With 2NO monitor contacts

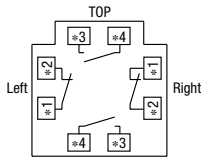


Applicable Crimping Terminal

Ring Terminal

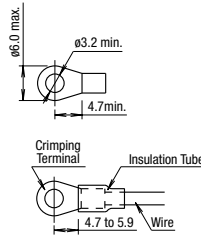


Spade Terminal

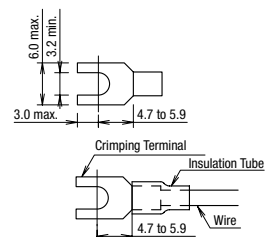

• Be sure to install an insulating tube on the crimping terminal.


Push-ON

NC main contacts only

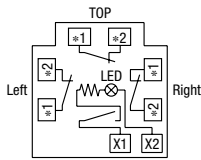


2NC: Terminals on right and left
3NC: Terminals on right, left, and top

With 1NO monitor contact

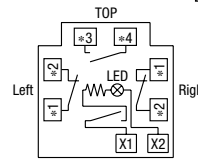


- * Contact
- 1-2: NC main contact (black)
- 3-4: NO monitor contact (blue)
- Contact Number (1-4) Starting with the contact of TOP side, in a counter-clockwise direction.

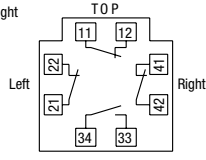

(Example: 1NO-3NC contact)


Solid Wire

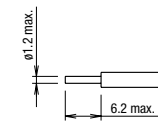

• Only solid wire can be used for IP20.


Illuminated

NC main contacts only

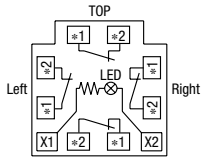


1NC: Terminals on right
2NC: Terminals on right and left
3NC: Terminals on right, left, and top

With 1NO monitor contact

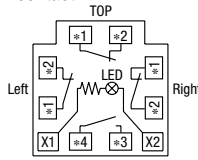

1NC: Terminals on top
2NC: Terminals on right and left

With 2NO monitor contacts

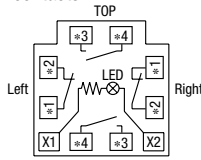

• See **D-050** for accessories and replacement parts.

All dimensions in mm.