

Part number

# CCMA 0.3



## Brief description:

16A CC contacts, silver plated, 0,14mmq - 0,37mmq, AWG 26 - 22

### Product description

<b>Model</b>	male contacts
<b>Version</b>	Crimp contacts CLASS series
<b>Series</b>	16A CC contacts
<b>Family</b>	crimp contacts
<b>N. of poles</b>	1 pole

### Technical data

<b>Current</b>	16 A
<b>Wire cross-section</b>	0,14 mm <sup>2</sup> - 0,37 mm <sup>2</sup>
<b>AWG size</b>	26 - 22
<b>Contact type</b>	silver plated

### Further technical details

<b>Weight</b>	1,60 g
---------------	--------

### Approvals / Standards

<b>Quality mark</b>	UL EAC
<b>Conformity</b>	CQC, CE

### General ordering information

<b>EAN13 code</b>	8015747170963
<b>Tariff number</b>	85369095

### Packaging Information

<b>Packaging length</b>	112,00 mm
<b>Packaging height</b>	95,00 mm
<b>Packaging width</b>	117,00 mm
<b>Packaging weight</b>	1,28 kg
<b>Packaging volume</b>	1,24 dm <sup>3</sup>
<b>Packaging description</b>	Carton box
<b>Packaging quantity</b>	800 Pcs
<b>Packaging EAN code</b>	8015747171014
<b>Sub-packaging length</b>	50,00 mm
<b>Sub-packaging height</b>	44,00 mm
<b>Sub-packaging width</b>	50,00 mm
<b>Sub-packaging weight</b>	0,16 kg
<b>Sub-packaging volume</b>	0,11 dm <sup>3</sup>
<b>Sub-packaging description</b>	Plastic box
<b>Sub-packaging quantity</b>	100 Pcs
<b>Sub-packaging EAN barcode</b>	8015747171021


Part number

# CCMA 0.3





## Catalogue drawings

**CCM**

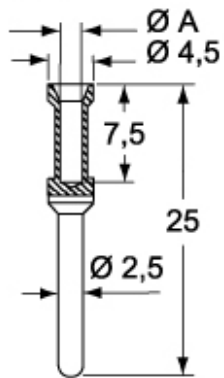

**CC...AN**

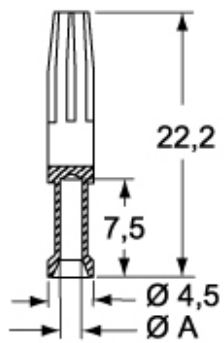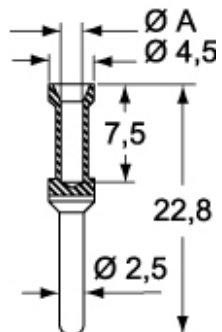

**CCF**