



Part number  
**CGFA 35**



**Brief description:**

100A CG contacts, silver plated, 35mmq, AWG 2

Product description	
Model	female contacts
Version	Crimp contacts CLASS series
Series	100A CG contacts
Family	crimp contacts
N. of poles	1 pole
Technical data	
Current	100 A
Wire cross-section	35,00 mm <sup>2</sup>
AWG size	2
Contact type	silver plated
Further technical details	
Weight	19,00 g

Approvals / Standards	
Quality mark	  EAC
Conformity	CQC, CE
General ordering information	
EAN13 code	8015747122689
Tariff number	85369095
Packaging Information	
Packaging length	132,00 mm
Packaging height	108,00 mm
Packaging width	210,00 mm
Packaging weight	2,85 kg
Packaging volume	2,99 dm <sup>3</sup>
Packaging description	Carton box
Packaging quantity	150 Pcs
Packaging EAN code	8015747225564
Sub-packaging length	1,00 mm
Sub-packaging height	1,00 mm
Sub-packaging width	1,00 mm
Sub-packaging weight	0,57 kg
Sub-packaging description	Plastic box
Sub-packaging quantity	30 Pcs
Sub-packaging EAN barcode	8015747122771



Part number

# CGFA 35



Catalogue drawings

**CGMA**

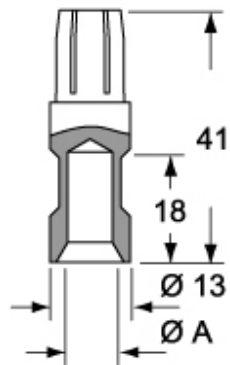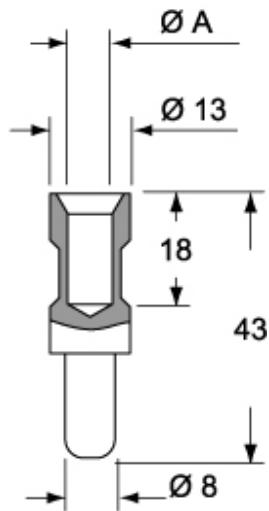

**CGFA**

---