

Part number

# CHC 32 G



## Brief description:

covers, size "77.62", metal version, IP65

### Product description

Version	metal version
Series	covers with levers
Product type	with 2 levers
Family	CLASS enclosures
Size	size "77.27", covers

### Technical data

Operating temperature range (min, max)	-40°C ... +125°C
Material	metal
IP degree of protection	IP65

### Further technical details

Weight	205,00 g
--------	----------

### Approvals / Standards

Quality mark	UL <sup>®</sup> (type:4/4X/12), <sup>®</sup> , EAC
Conformity	CQC, CE

### General ordering information

EAN13 code	8015747016544
Tariff number	85369095

### Packaging Information

Packaging length	240,00 mm
Packaging height	120,00 mm
Packaging width	355,00 mm
Packaging weight	4,10 kg
Packaging volume	10,22 dm <sup>3</sup>
Packaging description	Carton box
Packaging quantity	20 Pcs
Packaging EAN code	8015747202466
Sub-packaging weight	0,21 kg
Sub-packaging description	Plastic bag
Sub-packaging quantity	1 Pcs
Sub-packaging EAN barcode	8015747016551


Part number

# CHC 32 G




## Catalogue drawings


### CHC

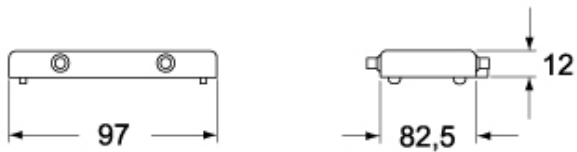


### CHC L

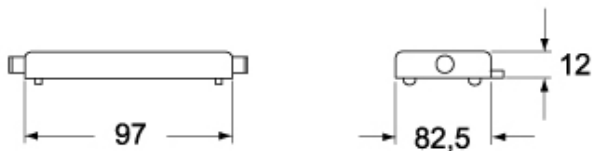

### CHC G

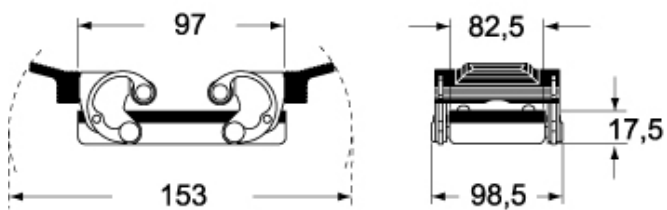

### CHC LG

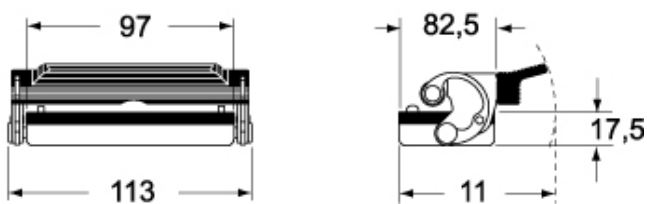

## Notes

The cover is not suitable to be used with code pins.

---