

Part number



CHCN 24



Brief description:

covers, size "104.27", connections for stage equipment, IP65


Product description	
Version	connections for stage equipment
Series	Covers
Product type	with 4 pegs
Family	LS-TYPE enclosures for stage equipment
Size	size "104.27", covers
Technical data	
Material	metal
IP degree of protection	IP65
Further technical details	
Weight	81,00 g

Approvals / Standards	
Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE
General ordering information	
EAN13 code	8015747187343
Tariff number	85369095
Packaging Information	
Packaging length	210,00 mm
Packaging height	130,00 mm
Packaging width	240,00 mm
Packaging weight	1,62 kg
Packaging volume	6,55 dm ³
Packaging description	Carton box
Packaging quantity	20 Pcs
Packaging EAN code	8015747191180
Sub-packaging weight	0,08 kg
Sub-packaging description	Plastic bag
Sub-packaging quantity	1 Pcs
Sub-packaging EAN barcode	8015747191197

Part number CHCN 24



Catalogue drawings

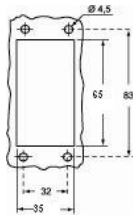

Catalogue drawings

CH..N - MF..N enclosures		size "104.27"	LS-TYPE version
<p>inserts: page</p> <p>CD 64 poles + @ 51+53 *</p> <p>CDD 108 poles + @ 64+66 *</p> <p>CQE 46 poles + @ 83+85 *</p> <p>CSH 24 poles + @ 91+93 *</p> <p>CCE 24 poles + @ 100+104 *</p> <p>CNE, CSE, JONE, JCSE 24 poles + @ 101 and 109 *</p> <p>CSS 24 poles + @ 121+123 *</p> <p>CMSE 10+2 (aux) poles + @ 139 *</p> <p>CMCE 10+2 (aux) poles + @ 138 *</p> <p>CX 4/8 poles + @ 155 *</p> <p>MIXO 6 modules 160+195 *</p> <p>insert centre distance: 104 x 27 mm</p> <p>* refer to catalogue page CN.12</p>	<p>hoods with 4 pegs</p>	<p>covers</p>	
<p>description</p> <p>with 2 levers and gasket, top entry</p> <p>with 2 levers and gasket, top entry, high construction</p> <p>covers with pegs</p> <p>covers with 2 levers</p>	<p>part no.</p> <p>MHVN 24 G32 32</p> <p>MFVN 24 G32 32</p>	<p>entry</p> <p>M</p>	<p>part no.</p> <p>CHCN 24</p> <p>CHCN 24 G</p>
<p>dimensions in mm</p> <p>MHVN 24 G32</p> <p>MFVN 24 G32</p>	<p>dimensions in mm</p> <p>CHCN 24</p> <p>CHCN 24 G</p>		
<p>- kiln powder coating with RAL 9005 black epoxy polyester powder</p> <p>- RAL 9005 black self-extinguishing thermoplastic locking lever (spare lever page 12)</p>			
<p> IP65</p> <p>dimensions shown are not binding and may be changed without notice</p>			