

Part number

# CHOR 10



## Brief description:

hoods for single lever, size "57.27", side entry, Pg16, 180 °C version, IP65

### Product description

|              |                            |
|--------------|----------------------------|
| Version      | 180 °C version             |
| Series       | hoods for single lever     |
| Product type | with 2 pegs                |
| Variant      | side entry                 |
| Family       | CLASS enclosures           |
| Size         | size "57.27" 180°C version |

### Technical data

|  |                  |
|--|------------------|
| Operating temperature range (min, max) | -40°C ... +180°C |
| Material                               | metal            |
| IP degree of protection                | IP65             |
| Cable entry                            | Pg16             |

### Further technical details

|        |          |
|--------|----------|
| Weight | 131,00 g |
|--------|----------|

### Approvals / Standards

|              |   |
|--------------|---|
| Quality mark |  (type:4/4X/12),  , EAC |
| Conformity   | CQC, CE   |

### General ordering information

|               |               |
|---------------|---------------|
| EAN13 code    | 8015747020527 |
| Tariff number | 85369095      |

### Packaging Information

|                           |                   |
|---------------------------|-------------------|
| Sub-packaging weight      | 0,13 kg           |
| Sub-packaging description | Plastic packaging |
| Sub-packaging quantity    | 1 Pcs             |
| Sub-packaging EAN barcode | 8015747020534     |


Part number

# CHOR 10




Catalogue drawings

## CHOR (CAOR) - MHOR (MAOR)

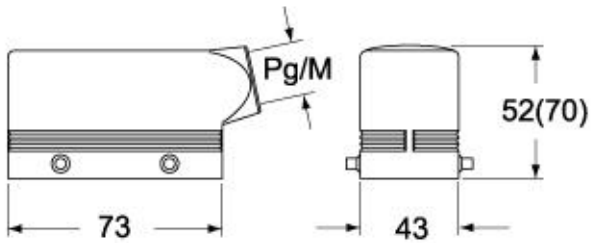

## CHVR (CAVR) - MHVR (MAVR)

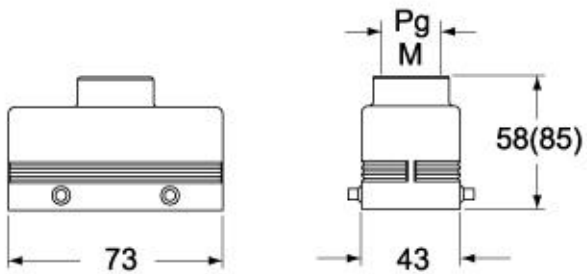

## CHCR G

