

Part number

CHOW 16



Brief description:

hoods for two levers, size "77.27", side entry, Pg21, aggressive environments, IP66

Product description

Version	W-TYPE version for aggressive environments
Series	hoods for two levers
Product type	with 4 pegs
Variant	side entry
Family	CLASS enclosures
Size	size "77.27"

Technical data

Material	metal
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)
Cable entry	Pg21

Further technical details

Weight	417,00 g
---------------	----------

Approvals / Standards

Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE

General ordering information

EAN13 code	8015747021227
Tariff number	85369095

Packaging Information

Sub-packaging weight	0,42 kg
Sub-packaging description	Plastic packaging
Sub-packaging quantity	1 Pcs
Sub-packaging EAN barcode	8015747021234


Part number

CHOW 16




Catalogue drawings


CHOW (CAOW) MHOW (MAOW)

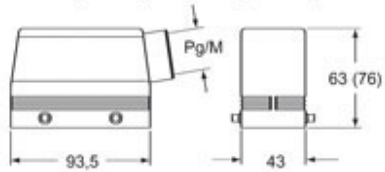

CHVW (CAVW) MHVW (MAVW)

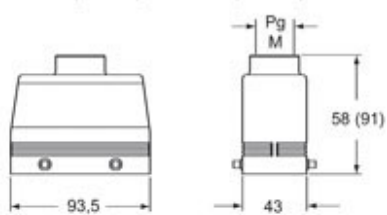

CHCW G

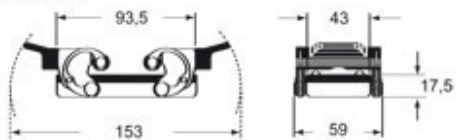

CAVW G MAVW G

