

Part number

# CKA 03 I



## Brief description:

bulkhead mounting housings with single lever, size "21.21", metal version, IP44, IP66/IP67 degree of protection with CKR 65 kit or CKR 65 D kit.

### Product description

<b>Version</b>	Metallic type
<b>Series</b>	Bulkhead mounting housings with 1 lever
<b>Product type</b>	with 1 lever in galvanised steel
<b>Family</b>	CKA metal enclosures
<b>Size</b>	size "21.21"


### Technical data

<b>Operating temperature range (min, max)</b>	-40°C ... +125°C
<b>Material</b>	metal
<b>IP degree of protection</b>	IP44 (IP66/IP67 with CKR 65/CKR 65 D kits)

### Further technical details

<b>Weight</b>	25,00 g
---------------	---------

### Approvals / Standards

<b>Quality mark</b>	UL type: 12, (type 4/4X only with kit CKR 65 or CKR 65 D),  , EAC
<b>Conformity</b>	CQC, CE

### General ordering information

<b>EAN13 code</b>	8015747026901
<b>Tariff number</b>	85369095

### Packaging Information


<b>Packaging length</b>	370,00 mm
<b>Packaging height</b>	135,00 mm
<b>Packaging width</b>	225,00 mm
<b>Packaging weight</b>	2,50 kg
<b>Packaging volume</b>	11,24 dm <sup>3</sup>
<b>Packaging description</b>	Carton box
<b>Packaging quantity</b>	100 Pcs
<b>Packaging EAN code</b>	8015747026918
<b>Sub-packaging length</b>	105,00 mm
<b>Sub-packaging height</b>	70,00 mm
<b>Sub-packaging width</b>	110,00 mm
<b>Sub-packaging weight</b>	0,25 kg
<b>Sub-packaging volume</b>	0,81 dm <sup>3</sup>
<b>Sub-packaging description</b>	Carton Box
<b>Sub-packaging quantity</b>	10 Pcs
<b>Sub-packaging EAN barcode</b>	8015747026925

Part number

# CKA 03 I





Catalogue drawings

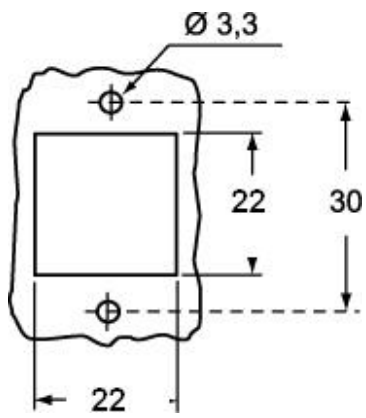

Catalogue drawings

**CKA I**

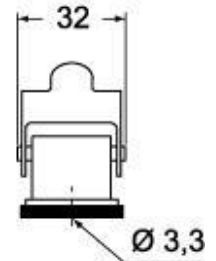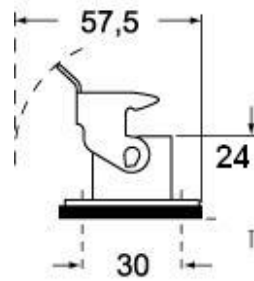

**CKAX I**

