

Part number

CKA 03 VAS



Brief description:

hoods for single lever, size "21.21", side entry, Pg11, metal version, IP44, IP66/IP67 degree of protection with CKR 65 kit or CKR 65 D kit.

Product description		Approvals / Standards	
Version	Metallic type	Quality mark	type: 12,(type 4/4X only with kit CKR 65 or
Series	Hoods with 2 pegs		CKR 65 D),  , EAC
Product type	with 2 pegs		CQC, CE
Variant	side entry	Conformity	
Family	CKA metal enclosures	General ordering information	
Size	size "21.21"	EAN13 code	8015747027052
Technical data		Tariff number	85369095
Operating temperature range (min, max)	-40°C ... +125°C	Packaging Information	
Material	metal	Packaging length	370,00 mm
IP degree of protection	IP44 (IP66/IP67 with CKR 65/CKR 65 D kits)	Packaging height	135,00 mm
Cable entry	Pg11	Packaging width	225,00 mm
Further technical details		Packaging weight	6,50 kg
Weight	65,00 g	Packaging volume	11,24 dm³
		Packaging description	Carton box
		Packaging quantity	100 Pcs
		Packaging EAN code	8015747233934
		Sub-packaging length	105,00 mm
		Sub-packaging height	70,00 mm
		Sub-packaging width	110,00 mm
		Sub-packaging weight	0,65 kg
		Sub-packaging volume	0,81 dm³
		Sub-packaging description	Carton Box
		Sub-packaging quantity	10 Pcs
		Sub-packaging EAN barcode	8015747027069

Part number

CKA 03 VAS



Catalogue drawings


CKA VS - MKA V



CKA VAS - MKA VA



CKA VAS - MKA VA

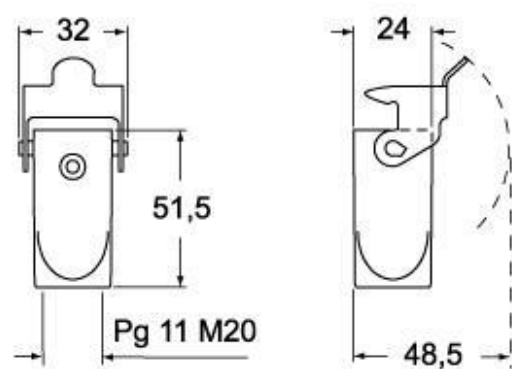

CKAX VGS - MKAX VG

