

Part number

CKAT 03.3 V



Brief description:

hoods for single lever, size "21.21", top entry, 3/8" NPT, metal version, IP44, IP66/IP67 degree of protection with CKR 65 kit or CKR 65 D kit.

Product description

Version	Metallic type
Series	Hoods with 2 pegs
Product type	with 2 pegs
Variant	top entry
Family	CKA metal enclosures
Size	size "21.21"


Technical data

Operating temperature range (min, max)	-40°C ... +125°C
Material	metal
IP degree of protection	IP44 (IP66/IP67 with CKR 65/CKR 65 D kits)
Cable entry	3/8" NPT

Further technical details

Weight	27,00 g
--------	---------

Approvals / Standards

Quality mark	UL type: 12, (type 4/4X only with kit CKR 65 or CKR 65 D),  , EAC
Conformity	CQC, CE

General ordering information

EAN13 code	8015747027335
Tariff number	85369095

Packaging Information

Packaging length	330,00 mm
Packaging height	170,00 mm
Packaging width	230,00 mm
Packaging weight	2,70 kg
Packaging volume	12,90 dm ³
Packaging description	Carton box
Packaging quantity	100 Pcs
Packaging EAN code	8015747234276
Sub-packaging length	105,00 mm
Sub-packaging height	70,00 mm
Sub-packaging width	110,00 mm
Sub-packaging weight	0,27 kg
Sub-packaging volume	0,81 dm ³
Sub-packaging description	Carton Box
Sub-packaging quantity	10 Pcs
Sub-packaging EAN barcode	8015747027342


Part number

CKAT 03.3 V




Catalogue drawings


CKA VS - MKA V

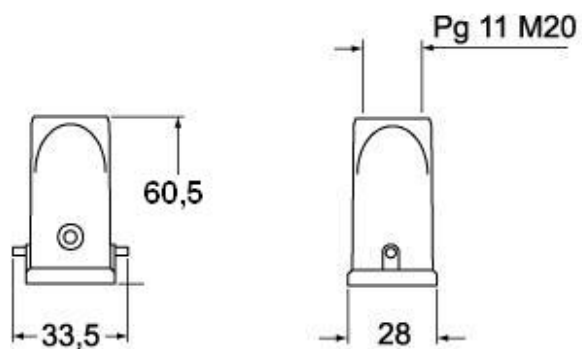

CKA VAS - MKA VA

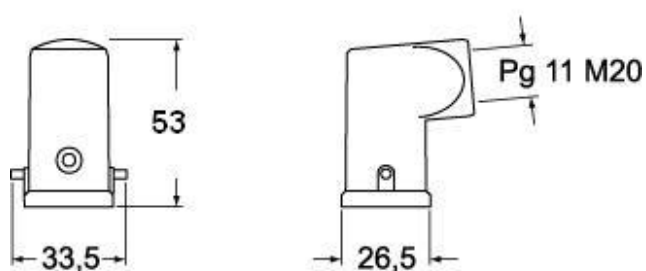

CKA VAS - MKA VA

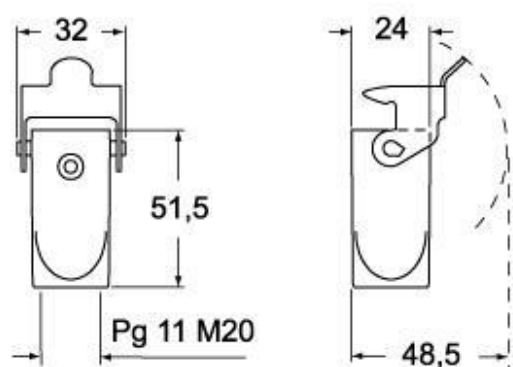

CKAX VGS - MKAX VG

