

Part number

CKAW 03 V



Brief description:

hoods for single lever, size "21.21", top entry, Pg11, aggressive environments, IP44, IP66/IP67 degree of protection with CKR 65 kit or CKR 65 D kit.

Product description

Version	W-TYPE version for aggressive environments
Series	hoods for single lever
Product type	with 2 pegs
Variant	top entry
Family	CLASS enclosures
Size	size "21.21"


Technical data

Operating temperature range (min, max)	-40°C ... +125°C
Material	metal
IP degree of protection	IP44 (IP66/IP67 with CKR 65/CKR 65 D kits)
Cable entry	Pg11

Further technical details

Weight	25,00 g
---------------	---------

Approvals / Standards

Quality mark	UL type: 12, (type 4/4X only with kit CKR 65 or CKR 65 D),  , EAC
Conformity	CQC, CE

General ordering information

EAN13 code	8015747027410
Tariff number	85369095

Packaging Information

Sub-packaging weight	0,03 kg
Sub-packaging description	Plastic bag
Sub-packaging quantity	1 Pcs
Sub-packaging EAN barcode	8015747230674


Part number

CKAW 03 V




Catalogue drawings

CKAW V MKAW V

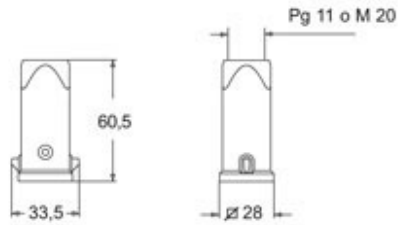

CKAW VA MKAW VA

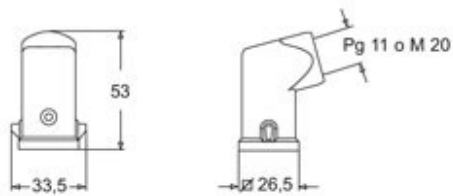

CKAXW VG MKAXW VG

