

Part number

# CKAX 03 I



## Brief description:

bulkhead mounting housings with single lever, size "21.21", metal version, IP44, IP66/IP67 degree of protection with CKR 65 kit or CKR 65 D kit.

### Product description

Version	Metallic type
Series	Bulkhead mounting housings with 1 lever
Product type	with stainless steel lever
Family	CKA metal enclosures
Size	size "21.21"


### Technical data

Operating temperature range (min, max)	-40°C ... +125°C
Material	metal
IP degree of protection	IP44 (IP66/IP67 with CKR 65/CKR 65 D kits)

### Further technical details

Weight	37,00 g
--------	---------

### Approvals / Standards

Quality mark	UL type: 12, (type 4/4X only with kit CKR 65 or CKR 65 D),  , EAC
Conformity	CQC, CE

### General ordering information

EAN13 code	8015747027519
Tariff number	85369095

### Packaging Information


Packaging length	370,00 mm
Packaging height	135,00 mm
Packaging width	225,00 mm
Packaging weight	3,90 kg
Packaging volume	11,24 dm <sup>3</sup>
Packaging description	Carton box
Packaging quantity	100 Pcs
Packaging EAN code	8015747230834
Sub-packaging length	105,00 mm
Sub-packaging height	70,00 mm
Sub-packaging width	110,00 mm
Sub-packaging weight	0,39 kg
Sub-packaging volume	0,81 dm <sup>3</sup>
Sub-packaging description	Carton Box
Sub-packaging quantity	10 Pcs
Sub-packaging EAN barcode	8015747027526

Part number

# CKAX 03 I





Catalogue drawings

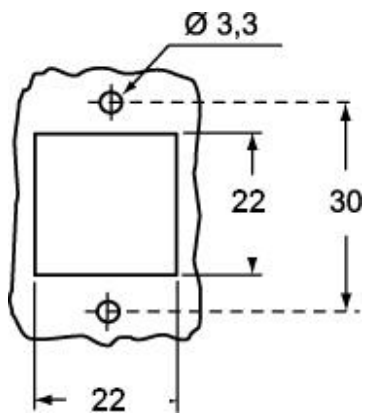

Catalogue drawings

CKA I

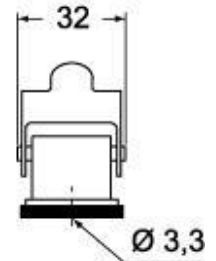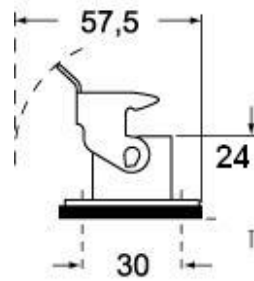

CKAX I

