



Part number

CKAX 03 ILS



Brief description:

bulkhead mounting housings with single lever, size "21.21", with metal cover, for female insert, metal version, IP44, IP66/IP67 degree of protection with CKR 65 kit or CKR 65 D kit.

Product description		Approvals / Standards	
Version	Metallic type	Quality mark	 type: 12, (type 4/4X only with kit CKR 65 or CKR 65 D),  , EAC
Series	Bulkhead mounting housings with 1 lever	Conformity	CQC, CE
Product type	with stainless steel lever	General ordering information	
Variant	with metal cover, for female insert	EAN13 code	8015747002417
Family	CKA metal enclosures	Tariff number	85369095
Size	size "21.21"	Packaging Information	
Technical data		Sub-packaging length	100,00 mm
Operating temperature range (min, max)	-40°C ... +125°C	Sub-packaging height	58,00 mm
Material	metal	Sub-packaging width	145,00 mm
IP degree of protection	IP44 (IP66/IP67 with CKR 65/CKR 65 D kits)	Sub-packaging weight	0,61 kg
Further technical details		Sub-packaging volume	0,84 dm ³
Weight	60,50 g	Sub-packaging description	Carton Box
		Sub-packaging quantity	10 Pcs
		Sub-packaging EAN barcode	8015747002431


Part number

CKAX 03 ILS




Catalogue drawings


panel cut-out for enclosures, dimensions in mm

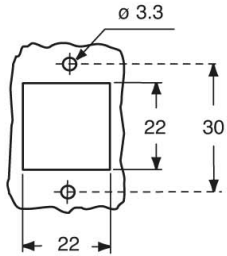


CKA ILS

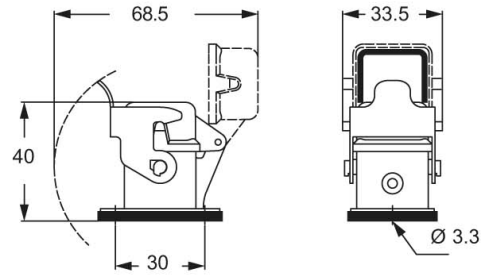

CKA ILSA

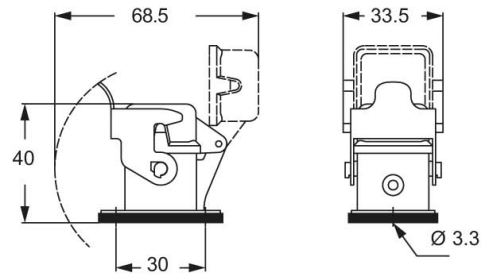

CKAX ILS

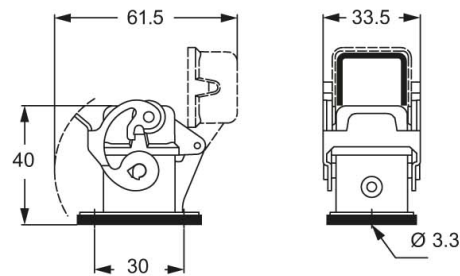

CKAX ILSA

