

Part number



CVI 10 LA



Brief description:

angled bulkhead housings with single lever, size "57.27", without cable gland, metal version, IP66

Product description	
Version	C7 - CV and M7 - MV enclosures, V-Type lever version
Series	Angled mounting housings with 1 lever
Product type	with stainless steel lever
Variant	without cable gland
Family	C7 - CV and M7 - MV enclosures, V-Type lever version
Size	size "57.27"
Technical data	
Material	metal
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)
Further technical details	
Weight	278,00 g

Approvals / Standards	
Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE
General ordering information	
EAN13 code	8015747191968
Tariff number	85369095
Packaging Information	
Packaging length	140,00 mm
Packaging height	120,00 mm
Packaging width	260,00 mm
Packaging weight	1,39 kg
Packaging volume	4,37 dm ³
Packaging description	Carton box
Packaging quantity	5 Pcs
Packaging EAN code	8015747191975
Sub-packaging weight	0,28 kg
Sub-packaging description	Plastic pakaging
Sub-packaging quantity	1 Pcs
Sub-packaging EAN barcode	8015747191982


Part number

CVI 10 LA



Catalogue drawings

CVI 10 LA

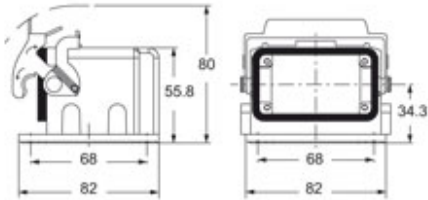

Notes

CVI 10 LA

Flange gasket to be purchased separately.

part No.: CR 10 MO

Kit with earthing contact, comprising a special screw and wire-terminals for 6 mm² earthing conductors (for the additional connection of the upper enclosure half)

part No.: CR MOT
