

Part number

CX 02 BF



Brief description:

female insert, seat for shielded connectors, 50V, 0,8kV, 3, two seats for shielded connectors, 2 modules, modular units series MIXO

Product description	
Model	female insert
Version	seat for shielded connectors
Product type	two seats for shielded connectors
Family	MIXO series, customizable inserts
Size	2 modules
Technical data	
Voltage	50 V
Rated impulse withstand voltage	0,8kV
Pollution degree	3
Operating temperature range (min, max)	-40°C ... +125°C
IP degree of protection	IP20 without enclosure; IP65/IP66/IP67/IP68 with enclosure
Further technical details	
Characteristics according to EN 61984	50V 0.8kV 3
Insulation resistance	≥ 10 GΩ
Rated voltage according to UL/CSA	50V
UL 94 flammability rating	V-0
Weight	14,00 g

Approvals / Standards	
Reference standard	EN 61984 (2001-11)
Quality mark	EAC
Conformity	CQC
General ordering information	
EAN13 code	8015747095914
Tariff number	85369095
Packaging Information	
Packaging length	145,00 mm
Packaging height	105,00 mm
Packaging width	350,00 mm
Packaging weight	2,00 kg
Packaging volume	5,33 dm ³
Packaging description	Carton box
Packaging quantity	60 Pcs
Packaging EAN code	8015747221047
Sub-packaging length	35,00 mm
Sub-packaging height	40,00 mm
Sub-packaging width	155,00 mm
Sub-packaging weight	0,17 kg
Sub-packaging volume	0,22 dm ³
Sub-packaging description	Carton
Sub-packaging quantity	5 Pcs
Sub-packaging EAN barcode	8015747095921


Part number

CX 02 BF




Catalogue drawings

CX 02 BM

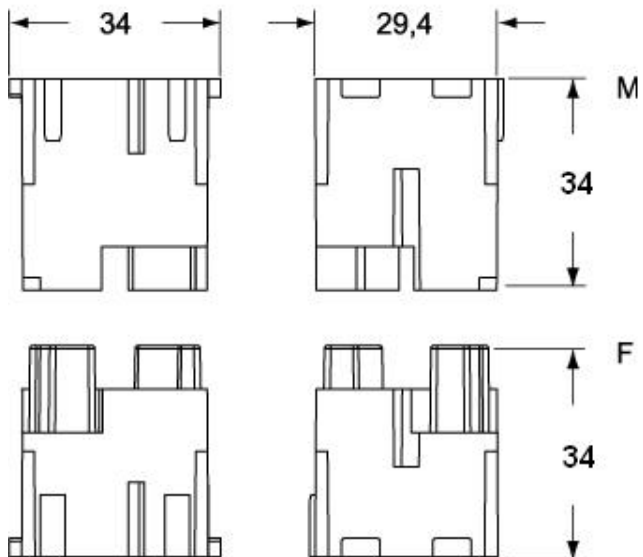

CX 02 BF

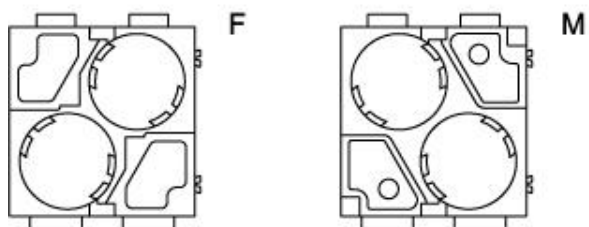

Notes

CX 02 B inserts:

- characteristics according to EN 61984:
(50V 0,8kV 3)

the modular inserts must be installed in suitable frames which in turn are installed in traditional housings or COB panel support
