

Part number

CZAO 25 L21



Brief description:

hoods for single lever, size "66.16", side entry, Pg21, metal version, IP66

Product description

Version	CZ levers, standard version
Series	Hoods with 2 pegs
Product type	with 2 pegs
Variant	side entry
Style	high construction
Family	CZ - MZ enclosures
Size	size "66.16"

Technical data

Operating temperature range (min, max)	-40°C ... +125°C
Material	metal
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)
Cable entry	Pg21

Further technical details

Weight	194,00 g
--------	----------

Approvals / Standards

Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE

General ordering information

EAN13 code	8015747043113
Tariff number	85369095

Packaging Information

Packaging length	150,00 mm
Packaging height	125,00 mm
Packaging width	225,00 mm
Packaging weight	1,85 kg
Packaging volume	4,22 dm ³
Packaging description	Carton box
Packaging quantity	10 Pcs
Packaging EAN code	8015747220439
Sub-packaging weight	0,93 kg
Sub-packaging description	Plastic packaging
Sub-packaging quantity	5 Pcs
Sub-packaging EAN barcode	8015747220446


Part number

CZAO 25 L21




Catalogue drawings


CZO L - MZO L

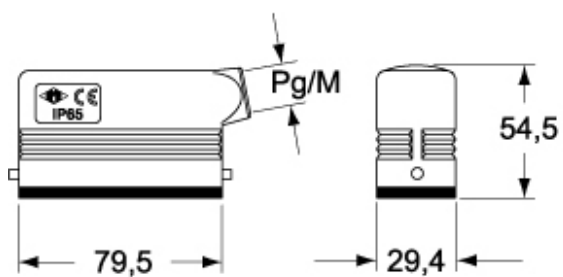

CZAO L MZAO L - CZAV L MZAV L

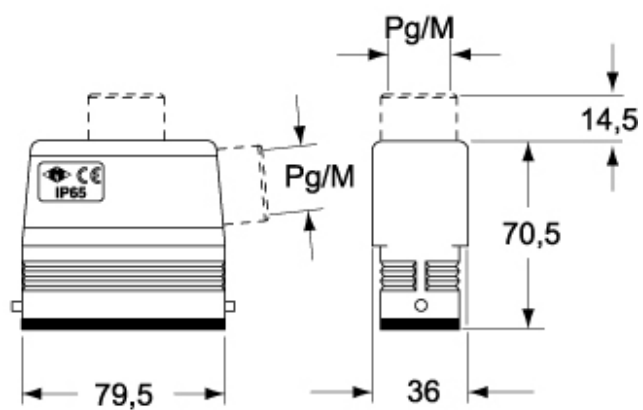

CZV L - MZV L

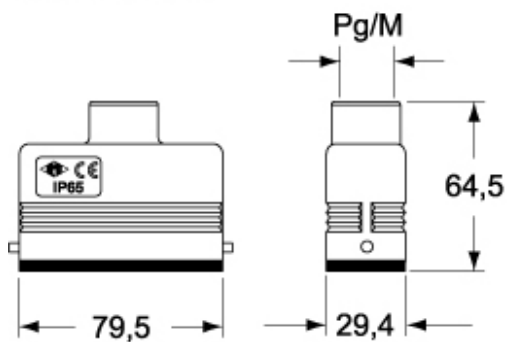

MZFO - MZFV L

