

Part number



# CZAV 15 L21



## Brief description:

hoods for single lever, size "49.16", top entry, Pg21, metal version, IP66

Product description	
Version	CZ levers, standard version
Series	Hoods with 2 pegs
Product type	with 2 pegs
Variant	top entry
Style	high construction
Family	CZ - MZ enclosures
Size	size "49.16"
Technical data	
Operating temperature range (min, max)	-40°C ... +125°C
Material	metal
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)
Cable entry	Pg21
Further technical details	
Weight	150,00 g

Approvals / Standards	
Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE
General ordering information	
EAN13 code	8015747043533
Tariff number	85369095
Packaging Information	
Packaging length	150,00 mm
Packaging height	125,00 mm
Packaging width	225,00 mm
Packaging weight	1,75 kg
Packaging volume	4,22 dm <sup>3</sup>
Packaging description	Carton box
Packaging quantity	10 Pcs
Packaging EAN code	8015747220682
Sub-packaging weight	0,88 kg
Sub-packaging description	Plastic packaging
Sub-packaging quantity	5 Pcs
Sub-packaging EAN barcode	8015747220699


Part number

# CZAV 15 L21




Catalogue drawings


## CZO L - MZO L

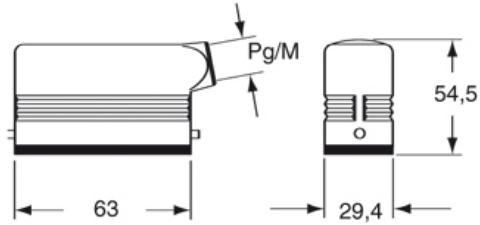

## CZAO L - MZAO L / CZAV L - MZAV L

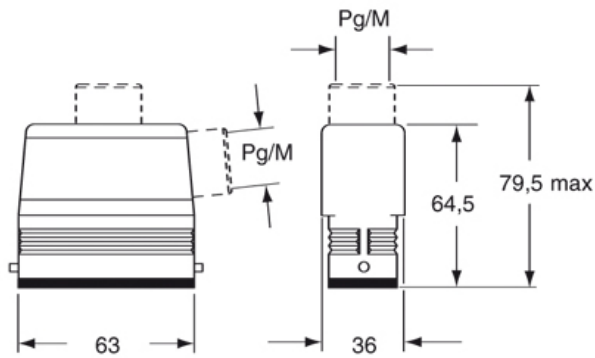

## CZV L - MZV L

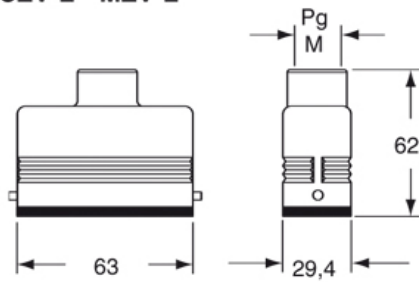

## CZFO L - MZFO L / CZFV L - MZFV L

