

Part number

CZAV 25 L216



Brief description:

hoods for single lever, size "66.16", double top entry, Pg16 x 2, metal version, IP66

Product description

Version	CZ levers, standard version
Series	Hoods with 2 pegs
Product type	with 2 pegs
Variant	double top entry
Style	high construction
Family	CZ - MZ enclosures
Size	size "66.16"

Technical data

Operating temperature range (min, max)	-40°C ... +125°C
Material	metal
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)
Cable entry	Pg16 x 2

Further technical details

Weight	195,00 g
--------	----------

Approvals / Standards

Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE

General ordering information

EAN13 code	8015747043632
Tariff number	85369095

Packaging Information

Packaging length	150,00 mm
Packaging height	125,00 mm
Packaging width	225,00 mm
Packaging weight	1,95 kg
Packaging volume	4,22 dm ³
Packaging description	Carton box
Packaging quantity	10 Pcs
Packaging EAN code	8015747228572
Sub-packaging weight	0,98 kg
Sub-packaging description	Plastic packaging
Sub-packaging quantity	5 Pcs
Sub-packaging EAN barcode	8015747228589


Part number

CZAV 25 L216



Catalogue drawings

CZAV L2 - (MZAV L2) - [MZFV L2]

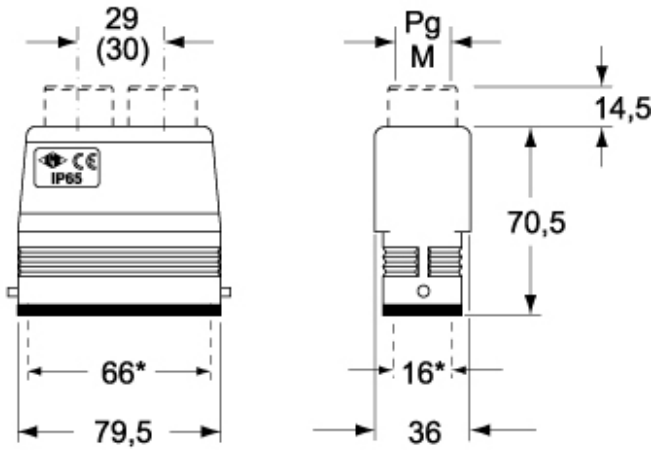

CAV - MAV - MFV

