

Part number

CZOW 15 L



Brief description:

hoods for single lever, size "49.16", side entry, Pg16, aggressive environments, IP66

Product description

Version	W-TYPE version for aggressive environments
Series	hoods for single lever
Product type	with 2 pegs
Variant	side entry
Family	CLASS enclosures
Size	size "49.16"



Technical data

Operating temperature range (min, max)	-40°C ... +125°C
Material	metal
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)
Cable entry	Pg16

Further technical details

Weight	87,00 g
---------------	---------

Approvals / Standards

Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE

General ordering information

EAN13 code	8015747044417
Tariff number	85369095

Packaging Information

Packaging weight	0,87 kg
Packaging volume	0,01 dm ³
Packaging description	Carton box
Packaging quantity	10 Pcs
Packaging EAN code	8015747171847
Sub-packaging length	120,00 mm
Sub-packaging height	105,00 mm
Sub-packaging width	160,00 mm
Sub-packaging weight	0,44 kg
Sub-packaging volume	2,02 dm ³
Sub-packaging description	Plastic pakaging
Sub-packaging quantity	5 Pcs
Sub-packaging EAN barcode	8015747171854


Part number

CZOW 15 L




Catalogue drawings


CZOW L MZOW L

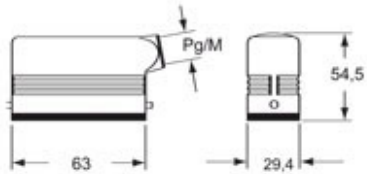

CZAOW L - MZAOW L CZAVV L - MZAVV L

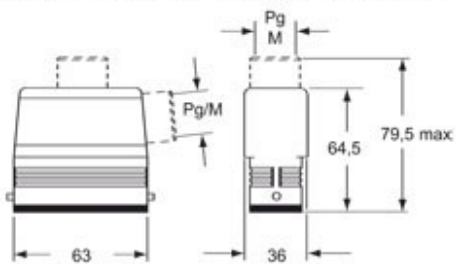

CZVW L MZVW L

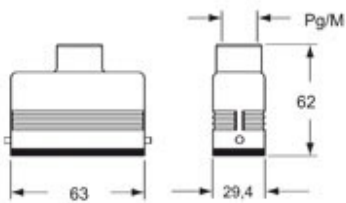

CZCW LG

