

Part number



CZOW 25 L



Brief description:

hoods for single lever, size "66.16", side entry, Pg16, aggressive environments, IP66

Product description	
Version	W-TYPE version for aggressive environments
Series	hoods for single lever
Product type	with 2 pegs
Variant	side entry
Family	CLASS enclosures
Size	size "66.16"
Technical data	
Operating temperature range (min, max)	-40°C ... +125°C
Material	metal
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)
Cable entry	Pg16
Further technical details	
Weight	104,00 g

Approvals / Standards	
Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE
General ordering information	
EAN13 code	8015747044431
Tariff number	85369095
Packaging Information	
Sub-packaging weight	1,04 kg
Sub-packaging description	Carton Box
Sub-packaging quantity	10 Pcs
Sub-packaging EAN barcode	8015747044448


Part number

CZOW 25 L




Catalogue drawings


CZOW L MZOW L

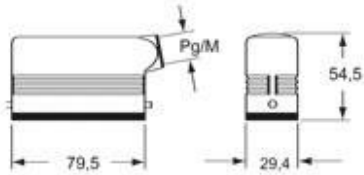

CZAOW L - MZAOW L CZAVV L - MZAVV L

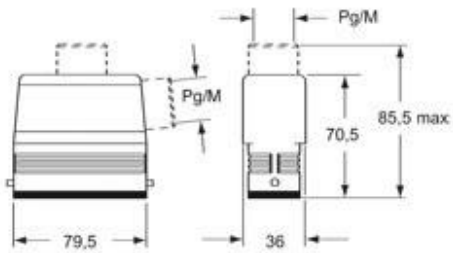

CZVW L MZVW L

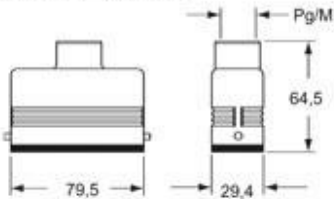

CZCW LG

