



Part number
JCVI 24



Brief description:

bulkhead mounting housings with 2 levers, size "104.27", metal version, IP66


Product description	
Version	JEI®-V enclosures
Series	bulkhead mounting housings with 2 levers
Product type	with 2 levers in galvanised steel
Family	Enclosures JEI® series, zinc plated levers
Size	size "104.27"
Technical data	
Material	metal
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)
Further technical details	
Weight	171,00 g

Approvals / Standards	
Quality mark	 (type:4/4X/12),  , EAC
Conformity	CQC, CE
General ordering information	
EAN13 code	8015747137577
Tariff number	85369095
Packaging Information	
Packaging length	365,00 mm
Packaging height	195,00 mm
Packaging width	305,00 mm
Packaging weight	6,83 kg
Packaging volume	21,71 dm ³
Packaging description	Carton box
Packaging quantity	40 Pcs
Packaging EAN code	8015747143950
Sub-packaging weight	0,85 kg
Sub-packaging description	Plastic pakaging
Sub-packaging quantity	5 Pcs
Sub-packaging EAN barcode	8015747140157

Part number
JCVI 24





Catalogue drawings

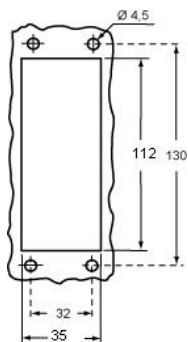

Catalogue drawings

JCVI

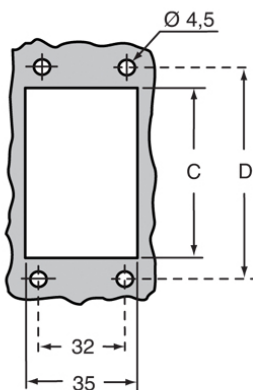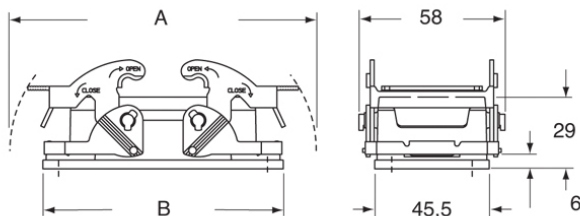

	A	B	C	D
JCVI 10	122	95,5	65	83
JCVI 16	142,5	115,5	86	103
JCVI 24	169	142,5	112	130