


Part number

JSHM 10



Product description

Model	male insert
Version	SQUICH® Spring connection contacts
Series	JSH
Product type	with male contacts
Family	JEI® inserts
Size	size "57.27"
N. of poles	10 poles + 



Technical data

Current	16 A (A.C. and D.C.)
Voltage	500 V
Rated impulse withstand voltage	6kV
Pollution degree	3
Wire cross-section	0,14 mm ² - 2,50 mm ²
AWG size	26 - 14
Operating temperature range (min, max)	-40°C ... +125°C
Contact type	tin plated
Mating cycles	≥ 200
IP degree of protection	IP20 without enclosure; IP65/IP66/IP67/IP68 with enclosure
PE wire cross-section	0,14 - 4 mm ² ; AWG 20 - 12

Further technical details

Characteristics according to EN 61984	16A 500V 6kV 3; 16A 400/690V 6kV 2
Insulation resistance	≥ 10 GΩ
Rated voltage according to UL/CSA	600V
UL 94 flammability rating	V-0
Weight	80,00 g

Approvals / Standards

Reference standard	EN 61984 (2001-11)
Quality mark	 ,  EAC
Conformity	CQC, CE

General ordering information

EAN13 code	8015747085151
Tariff number	85369095

Packaging Information

Packaging length	245,00 mm
Packaging height	165,00 mm
Packaging width	215,00 mm
Packaging weight	2,40 kg
Packaging volume	8,69 dm ³
Packaging description	Carton box
Packaging quantity	30 Pcs
Packaging EAN code	8015747085199
Sub-packaging weight	0,40 kg
Sub-packaging description	Carton
Sub-packaging quantity	5 Pcs
Sub-packaging EAN barcode	8015747085212



Part number

JSHM 10



Notes

actuator button connections

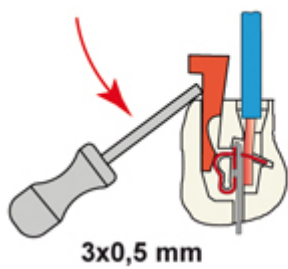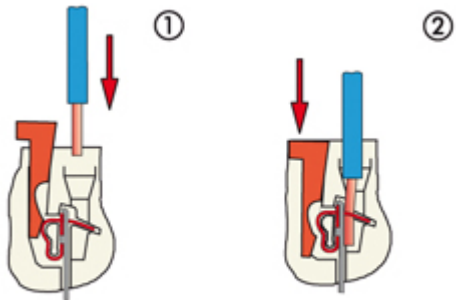

Reopening