

Part number

# MGK IAP20



## Brief description:

angled bulkhead mounting housings, screw locking, size "21.21", with threaded entry, M20, high protection IP68 version, IP68

### Product description

<b>Version</b>	high protection IP68 version
<b>Series</b>	angled bulkhead mounting housings, screw locking
<b>Product type</b>	for 2 screws
<b>Variant</b>	with threaded entry
<b>Family</b>	IP68 enclosures
<b>Size</b>	size "21.21"

### Technical data

<b>Operating temperature range (min, max)</b>	-40°C ... +125°C
<b>Material</b>	metal
<b>IP degree of protection</b>	IP68 (and IP69K DIN 40050 - 9)
<b>Cable entry</b>	M20

### Further technical details

<b>Weight</b>	164,00 g
---------------	----------

### Approvals / Standards

<b>Quality mark</b>	 (type:4/4X/12),  , EAC
<b>Conformity</b>	CQC, CE

### General ordering information

<b>EAN13 code</b>	8015747174572
<b>Tariff number</b>	85369095

### Packaging Information

<b>Packaging length</b>	150,00 mm
<b>Packaging height</b>	125,00 mm
<b>Packaging width</b>	225,00 mm
<b>Packaging weight</b>	1,64 kg
<b>Packaging volume</b>	4,22 dm <sup>3</sup>
<b>Packaging description</b>	Carton box
<b>Packaging quantity</b>	10 Pcs
<b>Packaging EAN code</b>	8015747174671
<b>Sub-packaging weight</b>	0,16 kg
<b>Sub-packaging description</b>	Plastic bag
<b>Sub-packaging quantity</b>	1 Pcs
<b>Sub-packaging EAN barcode</b>	8015747174688


Part number

# MGK IAP20




Catalogue drawings

CGK IAP - MGK IAP

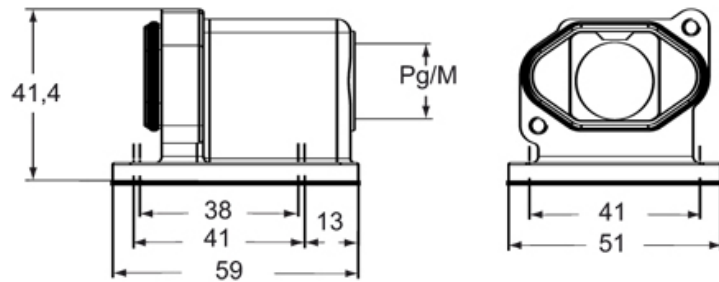

Catalogue drawings

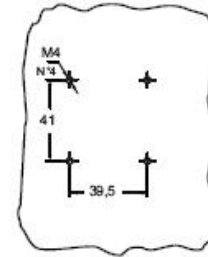

## Notes



- Please remove the insert screw and gasket
- Please use the screw and gasket provided with the housing