

Part number

CZAV 25 L21



Brief description:

hoods for single lever, size "66.16", top entry, Pg21, metal version, IP66

Product description		Approvals / Standards	
Version	CZ levers, standard version	Quality mark	 (type:4/4X/12),  , EAC
Series	Hoods with 2 pegs	Conformity	CQC, CE
Product type	with 2 pegs	General ordering information	
Variant	top entry	EAN13 code	8015747043618
Style	high construction	Tariff number	85369095
Family	CZ - MZ enclosures	Packaging Information	
Size	size "66.16"	Packaging length	150,00 mm
Technical data		Packaging height	125,00 mm
Operating temperature range (min, max)	-40°C ... +125°C	Packaging width	225,00 mm
Material	metal	Packaging weight	1,75 kg
IP degree of protection	IP66 (and IP69K DIN 40050 - 9)	Packaging volume	4,22 dm ³
Cable entry	Pg21	Packaging description	Carton box
Further technical details		Packaging quantity	10 Pcs
Weight	190,00 g	Packaging EAN code	8015747220729
		Sub-packaging weight	0,88 kg
		Sub-packaging description	Plastic packaging
		Sub-packaging quantity	5 Pcs
		Sub-packaging EAN barcode	8015747220736


Part number

CZAV 25 L21




Catalogue drawings


CZO L - MZO L

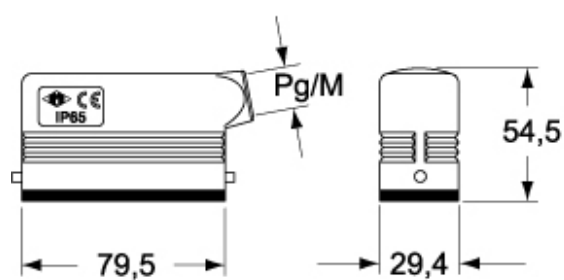

CZAO L MZAO L - CZAV L MZAV L

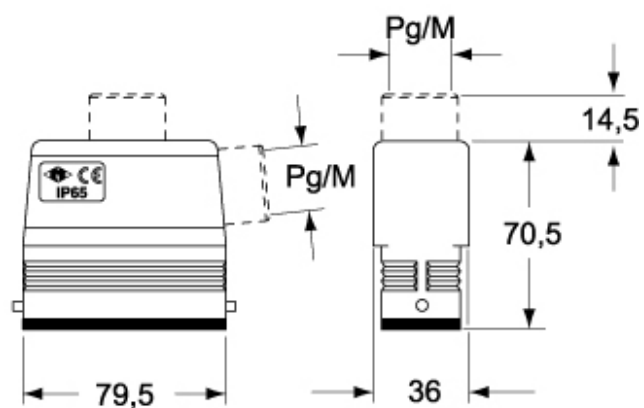

CZV L - MZV L

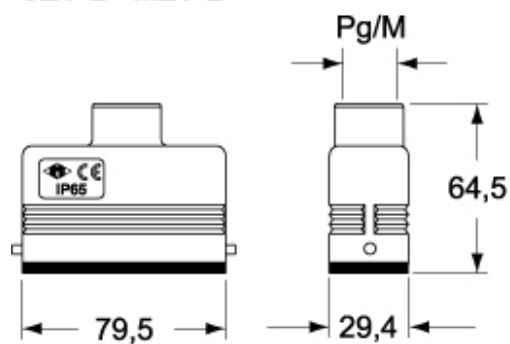

MZFO - MZFV L

