


IQ1500VS 120V/60HZ CAPACITY CHART

WATTS BTU/HR

879 3000
733 2500
586 2000
440 1500
293 1000
147 500
0 0

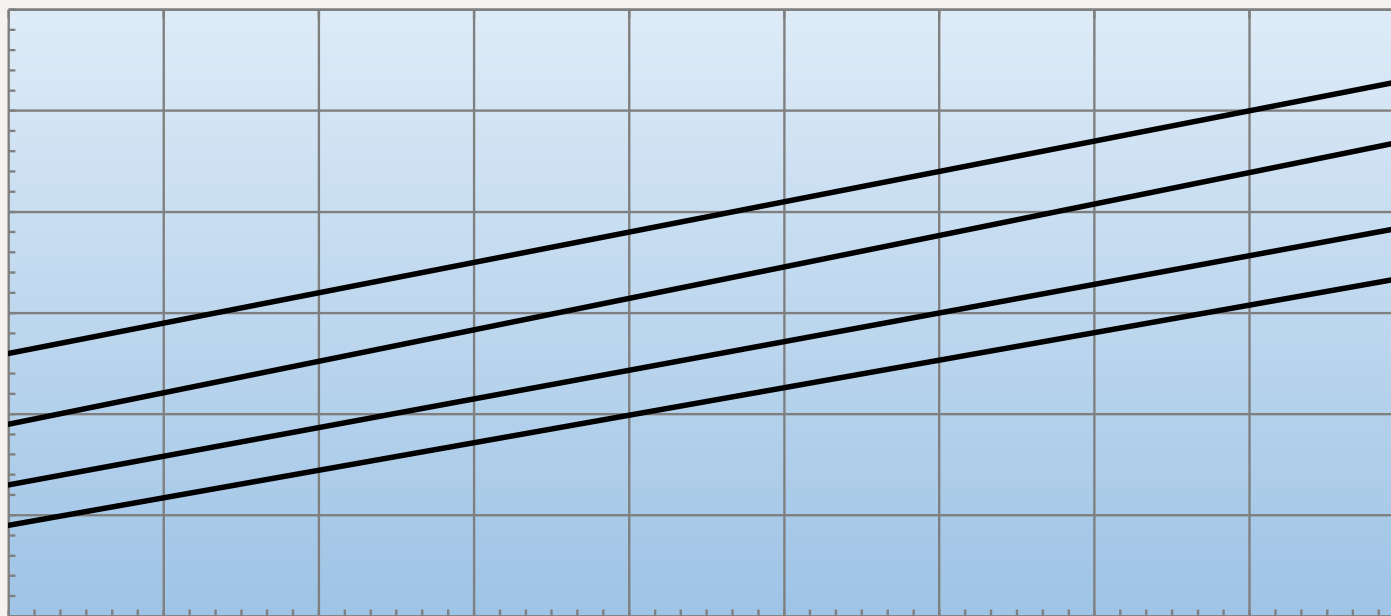

77°F/25°C
95°F/35°C
113°F/45°C
131°F/55°C

AMBIENT TEMPERATURE


77 83 89 95 101 107 113 119 125 131 °F
25.0 28.3 31.7 35.0 38.3 41.7 45.0 48.3 51.7 55.0 °C

RETURN AIR TEMPERATURE

IQ1500VS 230V/60HZ CAPACITY CHART

WATTS BTU/HR

879 3000
 733 2500
 586 2000
 440 1500
 293 1000
 147 500
 0 0

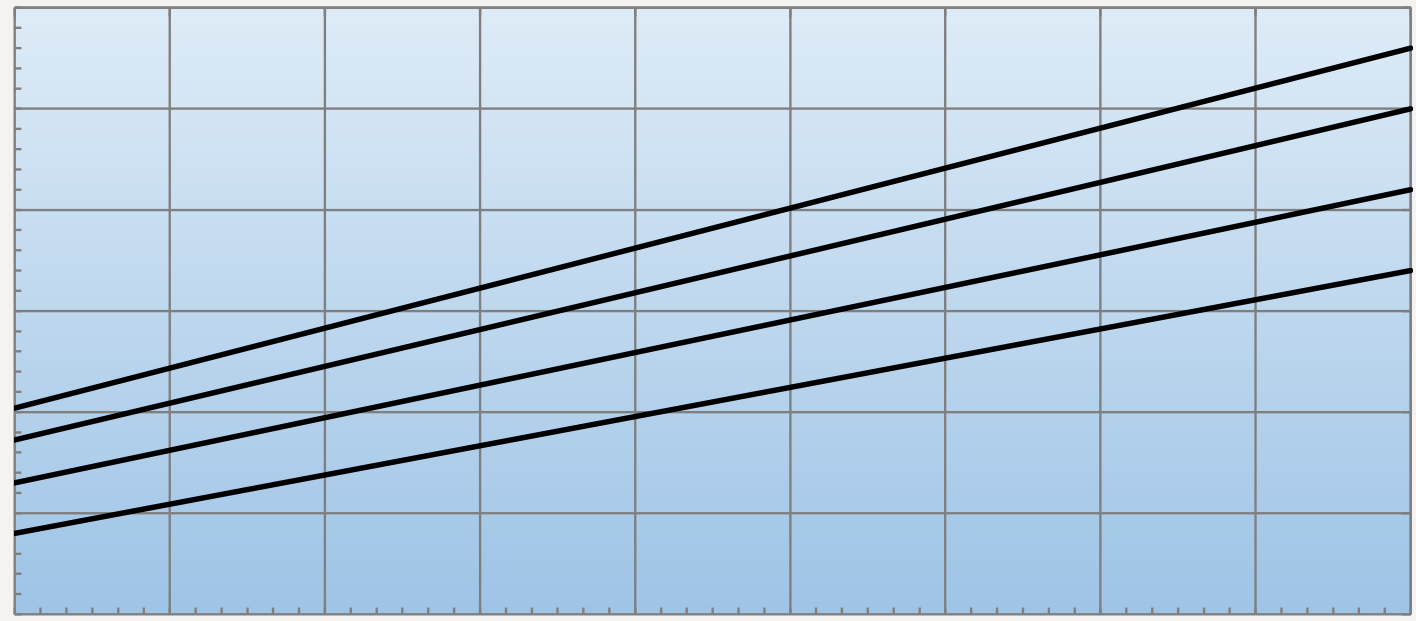

77 83 89 95 101 107 113 119 125 131 °F
 25.0 28.3 31.7 35.0 38.3 41.7 45.0 48.3 51.7 55.0 °C

RETURN AIR TEMPERATURE

AMBIENT TEMPERATURE

77°F/25°C
 95°F/35°C
 113°F/45°C
 131°F/55°C