

ST-B

Plugs for Membranes



Product Description

Plugs ST-B are used to seal already pierced membranes in various cable entry plates (KEL-DPU / KEL-DPZ / KEL-DP / KEL-QTA-DP) and DT grommets.

Perfect for applications where cables have been removed.

The IP rating of the cable entry plate remains.

Advantages & Benefits

- Sealing of pierced cable entry membranes which are no longer in use

Specifications

Material	Polyamide (PA), white
Flame class	UL94-Vo
Temperature	- 40°C to + 120°C - 40°F to + 248°F
Properties	Halogen-free, silicone-free


Compatible with

KEL-DPU Cable entry plates	62 - 63
KEL-DPZ Cable entry plates	64 - 71
KEL-DP Cable entry plates	72 - 75
DT Cable entry grommets	48
KEL-QTA-DP Cable entry plates	54

Type	Order No.	Diameter D1	Diameter D2	Length L	PU
ST-B 6	42806	8 mm	6 mm	16 mm	25
ST-B 10	42810	12 mm	10 mm	16 mm	25
ST-B 12	42812	15 mm	12 mm	16 mm	25
ST-B 16	42816	19 mm	16 mm	16 mm	25
ST-B 22	42822	25 mm	22 mm	21 mm	25
Assortment ST-B Plugs	42801	5× ST-B 6 5× ST-B 10 2× ST-B 12 1× ST-B 16 1× ST-B 22			

KEL-EMC-PF

Grounding Mount, Bracket Version

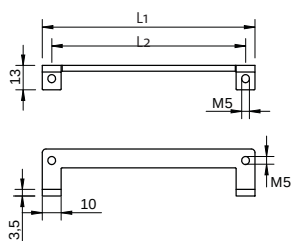

Type	Fits with	Order No.	Length L1	Length L2	PU
KEL-EMC-PF B4	KEL-E2 KEL-B KEL-U-B KEL-ER-B	39150	68 mm	58 mm	1
KEL-EMC-PF 10	KEL-E3 KEL 10 x KEL-U 10 x KEL-ER 10 x	39160	93 mm	83 mm	1
KEL-EMC-PF 16	KEL-E4 KEL 16 x KEL-U 16 x KEL-ER 16 x	39170	113 mm	103 mm	1
KEL-EMC-PF 24	KEL-E5 KEL 24 x KEL-U 24 x KEL-ER 24 x KEL-DPZ 24 x KEL-DPZ-E	39180	140 mm	130 mm	1

Product Description

The EMC bracket combined with the matching PFS|SKL EMC shield clamp is perfect in conjunction with the KEL cable entry frame for alleviating interferences due to shields.

The EMC clamp is assembled inside the control panel. For this process the same fixing screws for the assembly of the KEL frame on the control panel are used. A female screw thread M5 is already integrated in the KEL-EMC-PF bracket.

Depending on the cable diameter, the corresponding PFS|SKL EMC shield clamp can be snapped onto the EMC bracket.

Advantages & Benefits

- Supports a wide range of cable and wire sizes
- Large surface contact of the cable shield
- Permanent spring pressure on the cable shield
- Fast and easy assembly

Specifications

Material Carbon steel, galvanically zinc plated

Compatible with

KEL-U Cable entry frames	8 - 14
KEL-ER Cable entry frames	9 - 17
KEL Cable entry frames	16 - 27
KEL-QUICK Cable entry frames	50 - 51
KEL-BES Brush frames	57
KEL-DPU Cable entry plates	62 - 63
KEL-DPZ Cable entry plates	64 - 67
PFSZ SKL Shield clamps	100
PFS SKL Shield clamps	101