

KEL-DPZ 24

Cable Entry Plates



IP66



Also available in black.



Also available with threaded bushings.



Membrane on front

Product Description

2.1

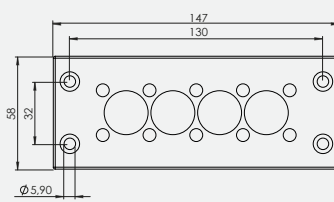
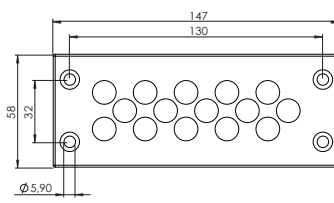
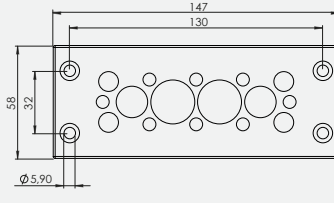
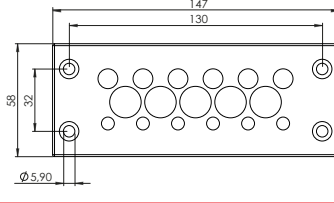
KEL-DPZ 24 entry plates are designed to route and seal up to 121 cables without connectors or fiber optics (from 1.5 mm to 22 mm in diameter) in limited space.

The KEL-DPZ products are a cost and time saving alternative to traditional cable glands.

The assembly of the KEL-DPZ 24 with cables or pneumatic hoses can be done quick and easy. Simply make a small hole in the thin membrane, push the cables through. The KEL-DPZ 24 provides strain relief and protection up to IP66 / UL type 12.

The size KEL-DPZ 24 matches exactly the cut-out dimensions of 24-pin standard industrial connectors.


ST-B Plugs can be used for sealing pierced membranes if cables have been removed.

Description	Type	Order No.	Number of cables	PU
	KEL-DPZ 24 14	 43700  50700	10× 3.2 - 6.5 mm / 0.126 - 0.248 " 4× 16 - 22 mm / 0.63 - 0.866 "	10
	KEL-DPZ 24 15	 43720  50720	15× 7.2 - 12 mm / 0.283 - 0.472 "	10
	KEL-DPZ 24 16	 43725  50725	8× 3.2 - 6.5 mm / 0.126 - 0.248 " 4× 5 - 9.7 mm / 0.197 - 0.382 " 2× 9 - 16.2 mm / 0.354 - 0.638 " 2× 16 - 22 mm / 0.63 - 0.866 "	10
	KEL-DPZ 24 17	 43705  50705	6× 3.2 - 6.5 mm / 0.126 - 0.248 " 6× 5 - 10.2 mm / 0.197 - 0.402 " 5× 9 - 16.2 mm / 0.354 - 0.638 "	10


* Only valid for gray product types

KEL-DPZ 24

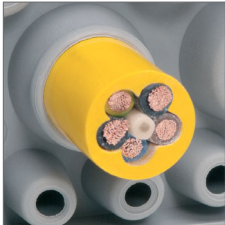Cable Entry Plates



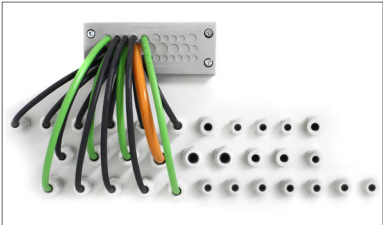Conical shape on back
provides additional sealing
and strain relief



High cable density



IP66

Description	Type	Order No.	Number of cables	PU
	KEL-DPZ 24 25	43710 50710	12× 3.2 - 6.5 mm / 0.126 - 0.248 " 7× 4.8 - 9.7 mm / 0.189 - 0.382 " 6× 7.5 - 12 mm / 0.295 - 0.472 "	10
	NEW KEL-DPZ 24 26	43711 50711	26× 5.0 - 10.2 mm / 0.2 - 0.4 "	10
	KEL-DPZ 24 32	43730 50730	21× 3.2 - 6.5 mm / 0.126 - 0.248 " 8× 5 - 10.2 mm / 0.197 - 0.402 " 3× 7.5 - 12 mm / 0.295 - 0.472 "	10
	KEL-DPZ 24 42	43715 50715	42× 3.2 - 6.5 mm / 0.126 - 0.248 "	10
	KEL-DPZ 24 121	43735 50735	119× 1.5 - 2.6 mm / 0.059 - 0.102 " 2× 2.5 - 5 mm 0.098 - 0.197 "	10

* Only valid for gray product types.

Advantages & Benefits

- Fast and easy assembly
- High cable density
- Dual sealing acc. to IP65/IP66/UL type 12
- Automatic sealing and strain relief for the cable
- Hygienic design

2.1

Specifications

Material	Frame: Polyamide (PA)
	Sealing plate: Elastomer
Color	gray (similar RAL 7035) black
Flame class	UL94-Vo
IP rating	IP65/IP66 (certified acc. to EN 60529)
UL type rating	UL type 12 (acc. to UL 50E)
Operating temperature	- 40°C to + 100°C (static) - 40°F to + 212°F (static)
Properties	Halogen-free, silicone-free
Cut-out dimensions	36 × 112 mm / 1.417 x 4.049 / page 220 - 221
Plate depth	14 mm

Accessories

ST-B Plugs	93
KEL-EMC-PF Grounding mounts	149
FP Flanged plates	194 - 203