


KB black Cable Ties



KBW 9

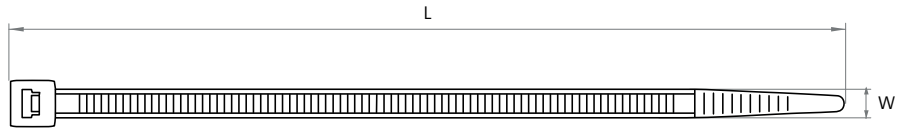

Product Description

Cable ties are proven utilities for economical bundling and fixing of cables, looms, tubes, conduits and many other components, e.g. for achieving strain relief.

Use highly flexible and strong power cable ties KB 28 for special requirements.

Specifications KB 28

Material Polyamide 12 (PA), black
 Flame class UL94-V2
 Temperature - 40°C to + 100°C
 - 40°F to + 212°F
 Properties Oil- and mould-resistant, highly flexible

Specifications KB black

Material Polyamide 6.6 (PA), black
 Flame class UL94-V2
 Temperature - 40°C to + 100°C
 - 40°F to + 212°F
 Properties UV-resistant, particularly suitable for outdoor use

Type	Order No.	Length L	Width W	Bundling range	Tensile strength	PU	
KB 28	61225	178 mm	9 mm	28 mm	350 N	100	
KB 20 bk	61215	98 mm	2.5 mm	20 mm	60 N	100	
KB 25 bk	61220	140 mm	3.6 mm	25 mm	130 N	100	
KB 30 bk	61230	160 mm	4.5 mm	30 mm	180 N	100	
KB 45 bk	61235	178 mm	4.8 mm	45 mm	220 N	100	
KB 55 bk	61240	200 mm	4.8 mm	50 mm	220 N	100	
KB 75 bk	61245	290 mm	4.8 mm	75 mm	220 N	100	
KB 100 bk	61250	360 mm	4.8 mm	100 mm	220 N	100	
KBW 9	61300	Processing tool for cable ties					1

3