



KBH

Holder for Hook-and-Loop Fastener

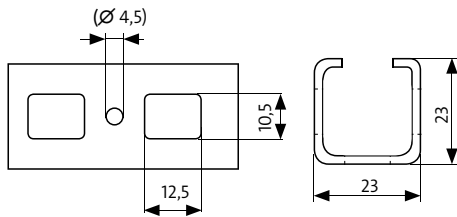

23 × 23 mm mounting rail

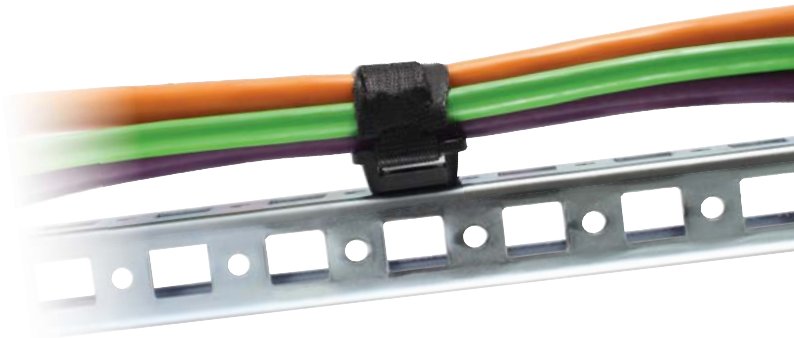

Description	Type	Order No.	fits KLKB KLB	Compatible with	PU
Holder for hook-and-loop fastener, screwable					
	KBH-S	■ 61019	KLKB 200 × 7 KLKB 200 × 13 KLB 10	23 × 23 mm mounting rail	100
	KBH-SB	■ 61002	KLKB 200 × 7	universal	100
Holder for hook-and-loop fastener, pluggable					
	KBH-R	■ 61018	KLKB 200 × 7 KLKB 200 × 13 KLB 10	23 × 23 mm mounting rail	100
	KBH-RBA nc	□ 61003	KLKB 200 × 7	drill-hole Ø 6 mm	100
	KBH-RBB	■ 61004	KLKB 200 × 7	drill-hole Ø 6.5 mm	100

* Only KBH-S / KBH-R

Product Description

These holders can be used in combination with hook-and-loop cable ties KLKB and hook-and-loop tape KLB.

A large variety of holders provides unique and numerous mounting possibilities.

Advantages

- Assembly within seconds
- Secure hold
- Flexible usage

Specifications KBH-S / KBH-R

Material	Polyamide (PA)
Color	■ black
Flame class	UL94-V0
Temperature	- 40°C to + 110°C - 40°F to + 230°F
Properties	Halogen-free, silicone-free

Specifications KBH-SB / KBH-RBA

Material	Polyamide (PA)
Color	■ black (KBH-SB) □ nc (KBH-RBA)
Flame class	UL94-V2
Temperature	- 40°C to + 85°C (short-term to 110°C) - 40°F to + 185°F (short-term to 230°F)

Specifications KBH-RBB

Material	Polyamide (PA)
Color	■ black
Temperature	- 40°C to + 120°C - 40°F to + 248°F

Compatible with

KLKB / KLB Cable ties with hook-and-loop fastener 90