


KB natural Cable Ties



KBW 9

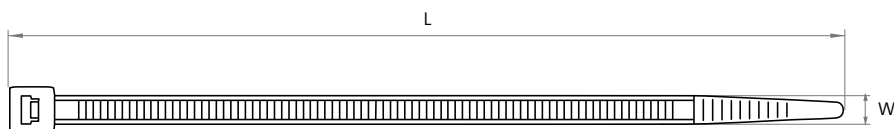

Type	Order No.	Length L	Width W	Bundling range	Tensile strength	PU	
KB 15 nc	61115	75 mm	2.2 mm	15 mm	60 N	100	
KB 20 nc	61120	98 mm	2.5 mm	20 mm	60 N	100	
KB 22 nc	61125	135 mm	2.6 mm	22 mm	80 N	100	
KB 25 nc	61130	140 mm	3.6 mm	25 mm	130 N	100	
KB 30 nc	61135	160 mm	4.5 mm	30 mm	180 N	100	
KB 45 nc	61140	178 mm	4.8 mm	45 mm	220 N	100	
KB 50 nc	61145	200 mm	2.6 mm	50 mm	80 N	100	
KB 55 nc	61150	200 mm	4.8 mm	50 mm	220 N	100	
KB 75 nc	61155	290 mm	4.8 mm	75 mm	220 N	100	
KB 100 nc	61160	360 mm	4.8 mm	100 mm	220 N	100	
KBW 9	61300	Processing tool for cable ties					1

Product Description

Cable ties are proven utilities for economical bundling and fixing of cables, looms, tubes, conduits and many other components, e.g. for achieving strain relief.

Specifications

Material	Polyamide 6.6 (PA), natural
Flame class	UL94-V2
Temperature	- 40°C to + 100°C - 40°F to + 212°F
Properties	Oil- and mould-resistant