


KDR-ESR

Enclosure Base Plate with Slide Frames

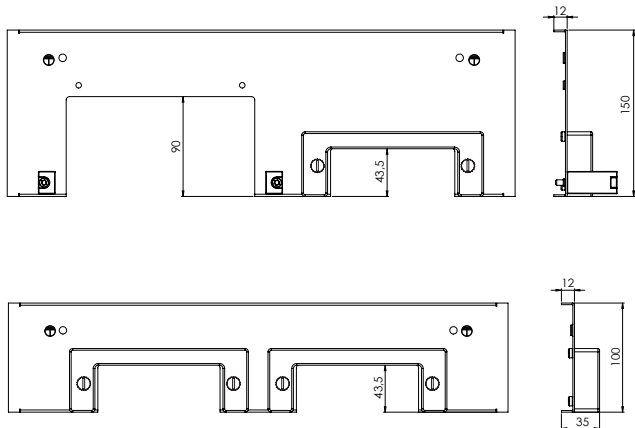

Sealing tape
Order No. 42999 (PU: 1 m)

Enclosure type	Enclosure width	Total length base plate	Sight size of base plate opening	No. of possible cable entries				Order No.
				JUMBO 1	JUMBO 2	KEL(-U) 16 ...	KEL(-U) 24 ...	
TS8	600 mm	458 mm	435 mm	-	-	-	2	43079
	600 mm	458 mm	435 mm	-	1	-	1	43070
	600 mm	458 mm	435 mm	1	-	2	-	43071
TS8	800 mm	658 mm	635 mm	-	-	1	3	43080
	800 mm	658 mm	635 mm	1	-	-	3	43072
	800 mm	658 mm	635 mm	-	1	-	2	43073
TS8	1000 mm without division bar	858 mm	835 mm	-	-	-	5	43081
	1000 mm without division bar	858 mm	835 mm	1	-	-	4	43074
	1000 mm without division bar	858 mm	835 mm	-	1	-	3	43075
TS8	1000 mm* with division bar	420 mm	398 mm	-	-	-	2	43082
	1000 mm* with division bar	420 mm	398 mm	1	-	-	1	43076
	1000 mm* with division bar	420 mm	398 mm	-	1	-	1	43077
TS8	1200 mm*	518 mm	495 mm	-	-	-	3	43083
	1200 mm*	518 mm	495 mm	1	-	-	2	43078
	1200 mm*	518 mm	495 mm	-	1	-	1	43084

* in case both fields of the enclosure are equipped, 2 complete base plates are necessary.