

KEL 16-MT

Extended Cable Entry Frames



IP54



V2A
anti-corrosive



Also available with stainless steel screws (V2A).



Also available with threaded bushings.

Product Description

The cable entry frame KEL 16-MT provides additional cable routing possibilities.

The KEL 16-MT series are KEL 16 frames extended with an additional middle frame for routing additional cables. Thus allowing the quick, easy and cost effective routing solution for up to 64 cables. A flat rubber gasket is included in the shipment.

Advantages & Benefits

- Warranty on pre-terminated cables remains
- Retrofits, repairs and maintenance can be done much more easily and quickly
- High cable density
- Strain relief according to EN 62444
- High stability, vibration resistant

Specifications

Material	Polyamide (PA)
Flame class	UL94-Vo
IP Rating	IP54, with gasket and correct selection of the grommets (certified acc. to EN 60529)
Temperature	- 40°C to + 140°C (static) - 40°F to + 284°F (static)
Properties	Halogen-free, silicone-free
Cut-out dimensions	82 × 86 mm
Frame depth	17 mm

Accessories

Cable grommets	44 - 48
KEL-EMC Grounding mounts	122 - 124


Description

Type

Order No.

Grommets
small | large

PU

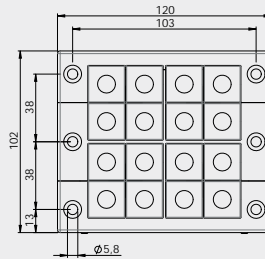

KEL 16|16-MT

42145

16|-


1

KEL 16|16-MT
with V2A screws

42145.200

16|-

1

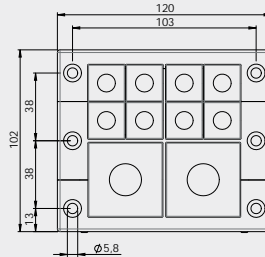

KEL 16|10-MT

42144

8|2


1

KEL 16|10-MT
with V2A screws

42144.200

8|2

1

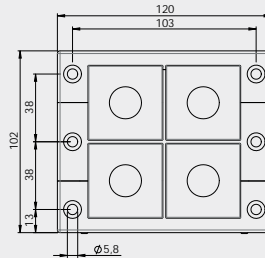

KEL 16|4-MT

42143

-|4

1

KEL 16|4-MT
with V2A screws

42143.200

-|4

1