


# KVT-SNAP

## Pluggable Split Cable Glands

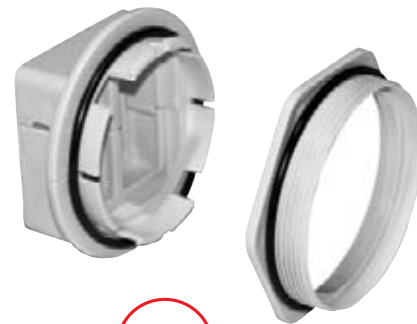

1

Type	Order No.	Grommets small   large	Thread Thread length	PU	Description
KVT-SNAP 32	45130	1 -	M32 x 1.5 Length: 11 mm	10	
KVT-SNAP 40	45134	1 -	M40 x 1.5 Length: 11 mm	10	
KVT-SNAP 63 4	45152	4 -	M63 x 1.5 Length: 11 mm	5	
KVT-SNAP 63 1	45154	- 1	M63 x 1.5 Length: 11 mm	5	
KGM 32	<input type="checkbox"/> 52275 <input checked="" type="checkbox"/> 52285	PA	M32 x 1.5	10	
KGM 40	<input type="checkbox"/> 52276 <input checked="" type="checkbox"/> 52286	PA	M40 x 1.5	10	
KGM 63	<input type="checkbox"/> 52278 <input checked="" type="checkbox"/> 52288	PA	M63 x 1.5	5	

### Product Description

KVT is a circular split frame for quick and easy installation of cables with connectors or complete cable harnesses.

By using the model KVT-SNAP, cables can be routed through thick walls (> 5 mm) e.g. into cast junction boxes without the use of tools.

A sealing ring is included in the shipment.

### Assembly

- The snap ring is screwed into metric thread or tapped into the cut-out (it can also be fastened with a locknut)
- Once the snap ring is affixed to the housing the equipped KVT is simply pushed into it. Fast and easy installation!

### Specifications

Material	Polycarbonate (PC)
Color	gray (similar RAL 7035)
Flame class	UL94-Vo
IP Rating	<input type="checkbox"/> IP54, with gasket and correct selection of the cable grommets (certified acc. to EN 60529)
Temperature	- 30°C to + 100°C (static) - 22°F to + 212°F (static)
Properties	Halogen-free, silicone-free
Cut-out dimension	Metric cut-outs

### Accessories

Cable grommets	44 - 48
KVT-EMC Brackets	125
KGM Locknuts	162 -163