

KEL-ER-BS cable entry frames with fire penetration seals (EN 45545-3)

for cables with connectors / IP66 / UL Type 12/4X



icotek cable entry frames with fire penetration seals, approved for use in railway technology (meeting the standards EN 45545-2, EN 45545-3 and EN 1363-1).

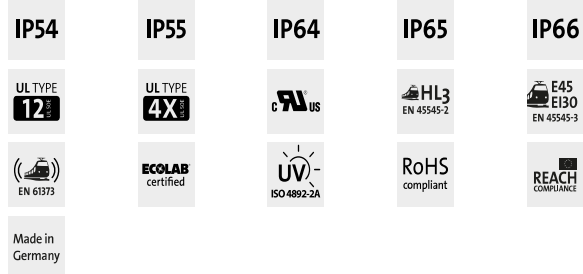
Split cable entry system for routing and sealing cables with connectors, providing an IP66 / UL type 12/4X rating and strain relief for cable diameters from 1 to 16 mm (single-hole grommets KT 1 - 15) and 16 to 35 mm (single-hole grommets KT 16 - 34).

The cable entry system is easy to install. Cable grommets are placed into compartments and are securely fixed to the frame during assembly.

The KEL-ER-BS frame matches exactly the cut-out dimensions for 10-, 16- and 24-pin standard industrial connectors. The KEL-ER-B-BS frame matches exactly the cut-out dimensions of 46 x 46 mm measuring instruments. The single-row version KEL-ER-E-BS is particularly suited for flat connectors. The small frame is ideal for applications with limited space. A flat rubber gasket is included in the shipment.

The intumescent (foaming) IFPS fire penetration seals which are mounted at the backside of the cable entry components consist of expandable graphite and increase their volume by a multiple in case of a fire.

This creates a barrier which prevents a penetration of flames and high heat from one room into another for the longest possible period.



Specifications

 
IP rating (EN 60529)	IP54, IP55, IP64, IP65, IP66
UL Type (UL 50E)	UL Type 12, UL Type 4X
Material	Polyamide
Flame class	UL94-V0, self-extinguishing
Operating temperature	-40 C° to 140 C°
Properties	silicone free, halogen free, intumescent (foaming), anti-corrosive (V2A versions)
Mounting options	Screw type mounting

Advantages & Benefits

 
- Approved for use in railway technology (EN 45545-2, EN 45545-3, EN 1363-1 and EN 61373)
- Only one fire penetration seal per cable entry component required
- High classifications E45 / EI30
- Warranty on pre-terminated cables remains
- Retrofits, repairs and maintenance can be done much more easily and quickly
- High cable density, wide variety of grommets
- Strain relief according to EN 62444
- High stability, vibration resistant
- Space-saving shape
- Perfect for routing D-Sub connectors

Product types & Sizes

 
KEL-ER 24|10-BS



 
Part No.	99300.006	Height	17 mm
EAN	4251269318467	Mounting height	17 mm
PU	5	Cut-out size	112 x 36 mm
For max. no. of cables	10	No. of screw holes	4
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	147 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	10 x KT small

KEL-ER 24|10-BS V2A

Part No.	99300.206	Height	17 mm
EAN	4251269318818	Mounting height	17 mm
PU	5	Cut-out size	112 x 36 mm
For max. no. of cables	10	No. of screw holes	4
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	147 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	10 x KT small

KEL-ER 24|7-BS

Part No.	99300.005	Height	17 mm
EAN	4251269318450	Mounting height	17 mm
PU	5	Cut-out size	112 x 36 mm
For max. no. of cables	7	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	147 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	6 x KT small 1 x KT large

KEL-ER 24|7-BS V2A

 
Part No.	99300.205	Height	17 mm
EAN	4251269318801	Mounting height	17 mm
PU	5	Cut-out size	112 x 36 mm
For max. no. of cables	7	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	147 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	6 x KT small 1 x KT large

KEL-ER 24|4-BS

 
Part No.	99300.004	Height	17 mm
EAN	4251269318443	Mounting height	17 mm
PU	5	Cut-out size	112 x 36 mm
For max. no. of cables	4	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	147 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	2 x KT small 2 x KT large

KEL-ER 24|4-BS V2A

 
Part No.	99300.204	Height	17 mm
EAN	4251269318795	Mounting height	17 mm
PU	5	Cut-out size	112 x 36 mm
For max. no. of cables	4	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	147 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	2 x KT small 2 x KT large

KEL-ER 16|8-BS

 
Part No.	99301.006	Height	17 mm
EAN	4251269318528	Mounting height	17 mm
PU	5	Cut-out size	86 x 36 mm
For max. no. of cables	8	No. of screw holes	4
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	120 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	8 x KT small

KEL-ER 16|8-BS V2A

Part No.	99301.206	Height	17 mm
EAN	4251269318870	Mounting height	17 mm
PU	5	Cut-out size	86 x 36 mm
For max. no. of cables	8	No. of screw holes	4
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	120 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	8 x KT small

KEL-ER 16|5-BS

Part No.	99301.005	Height	17 mm
EAN	4251269318511	Mounting height	17 mm
PU	5	Cut-out size	86 x 36 mm
For max. no. of cables	5	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	120 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	4 x KT small 1 x KT large

KEL-ER 16|5-BS V2A

 
Part No.	99301.205	Height	17 mm
EAN	4251269318863	Mounting height	17 mm
PU	5	Cut-out size	86 x 36 mm
For max. no. of cables	5	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	120 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	4 x KT small 1 x KT large

KEL-ER 16|2-BS

 
Part No.	99301.004	Height	17 mm
EAN	4251269318504	Mounting height	17 mm
PU	5	Cut-out size	86 x 36 mm
For max. no. of cables	2	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	120 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	2 x KT large

KEL-ER 16|2-BS V2A

 
Part No.	99301.204	Height	17 mm
EAN	4251269318856	Mounting height	17 mm
PU	5	Cut-out size	86 x 36 mm
For max. no. of cables	2	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	120 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	2 x KT large

KEL-ER 10|6-BS

 
Part No.	99306.003	Height	17 mm
EAN	4251269320668	Mounting height	17 mm
PU	5	Cut-out size	65 x 36 mm
For max. no. of cables	6	No. of screw holes	4
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	98 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	6 x KT small

KEL-ER 10|6-BS V2A

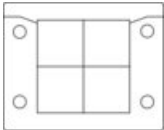
Part No.	99306.203	Height	17 mm
EAN	4251269321948	Mounting height	17 mm
PU	5	Cut-out size	65 × 36 mm
For max. no. of cables	6	No. of screw holes	4
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	98 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	6 x KT small

KEL-ER 10|3-BS

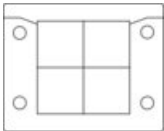
Part No.	99306.004	Height	17 mm
EAN	4251269320675	Mounting height	17 mm
PU	5	Cut-out size	65 × 36 mm
For max. no. of cables	3	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	98 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	2 x KT small 1 x KT large

KEL-ER 10|3-BS V2A

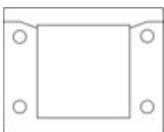
Part No.	99306.204	Height	17 mm
EAN	4251269321955	Mounting height	17 mm
PU	5	Cut-out size	65 × 36 mm
For max. no. of cables	3	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	98 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	2 x KT small 1 x KT large

KEL-ER-B4-BS

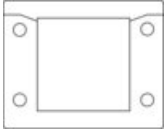
Part No.	99305.004	Height	17 mm
EAN	4251269320637	Mounting height	17 mm
PU	5	Cut-out size	46 × 46 mm
For max. no. of cables	4	No. of screw holes	4
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	73 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	4 x KT small

KEL-ER-B4-BS V2A

Part No.	99305.204	Height	17 mm
EAN	4251269321917	Mounting height	17 mm
PU	5	Cut-out size	46 × 46 mm
For max. no. of cables	4	No. of screw holes	4
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	73 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	4 x KT small

KEL-ER-B1-BS

Part No.	99305.003	Height	17 mm
EAN	4251269320620	Mounting height	17 mm
PU	5	Cut-out size	46 × 46 mm
For max. no. of cables	1	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	73 mm	Screw material	Stahl, galvanisch verzinkt
Width	58 mm	Suitable for grommets	1 x KT large 0 x KT small

KEL-ER-B1-BS V2A

Part No.	99305.203	Height	17 mm
EAN	4251269321900	Mounting height	17 mm
PU	5	Cut-out size	46 x 46 mm
For max. no. of cables	1	No. of screw holes	4
Max. cable diameter	35 mm	Diam. of screw holes	5,8 mm
Length	73 mm	Screw material	Edelstahl V2A
Width	58 mm	Suitable for grommets	1 x KT large 0 x KT small

KEL-ER-E5-BS

Part No.	99302.002	Height	17 mm
EAN	4251269318542	Mounting height	17 mm
PU	5	Cut-out size	112 x 24 mm
For max. no. of cables	5	No. of screw holes	2
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	147 mm	Screw material	Stahl, galvanisch verzinkt
Width	39 mm	Suitable for grommets	5 x KT small

KEL-ER-E5-BS V2A

Part No.	99302.202	Height	17 mm
EAN	4251269318894	Mounting height	17 mm
PU	5	Cut-out size	112 x 24 mm
For max. no. of cables	5	No. of screw holes	2
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	147 mm	Screw material	Edelstahl V2A
Width	39 mm	Suitable for grommets	5 x KT small

KEL-ER-E4-BS

 
Part No.	99309.002	Height	17 mm
EAN	4251269321801	Mounting height	17 mm
PU	5	Cut-out size	86 x 24 mm
For max. no. of cables	4	No. of screw holes	2
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	120 mm	Screw material	Stahl, galvanisch verzinkt
Width	39 mm	Suitable for grommets	4 x KT small

KEL-ER-E4-BS V2A

 
Part No.	99309.202	Height	17 mm
EAN	4251269321825	Mounting height	17 mm
PU	5	Cut-out size	86 x 24 mm
For max. no. of cables	4	No. of screw holes	2
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	120 mm	Screw material	Edelstahl V2A
Width	39 mm	Suitable for grommets	4 x KT small

KEL-ER-E3-BS

 
Part No.	99308.002	Height	17 mm
EAN	4251269321764	Mounting height	17 mm
PU	5	Cut-out size	65 x 24 mm
For max. no. of cables	3	No. of screw holes	2
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	98 mm	Screw material	Stahl, galvanisch verzinkt
Width	39 mm	Suitable for grommets	3 x KT small

KEL-ER-E3-BS V2A

Part No.	99308.202	Height	17 mm
EAN	4251269321788	Mounting height	17 mm
PU	5	Cut-out size	65 x 24 mm
For max. no. of cables	3	No. of screw holes	2
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	98 mm	Screw material	Edelstahl V2A
Width	39 mm	Suitable for grommets	3 x KT small

KEL-ER-E2-BS

Part No.	99307.002	Height	17 mm
EAN	4251269321726	Mounting height	17 mm
PU	5	Cut-out size	43 x 24 mm
For max. no. of cables	2	No. of screw holes	2
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	73 mm	Screw material	Stahl, galvanisch verzinkt
Width	39 mm	Suitable for grommets	2 x KT small

KEL-ER-E2-BS V2A

Part No.	99307.202	Height	17 mm
EAN	4251269321740	Mounting height	17 mm
PU	5	Cut-out size	43 x 24 mm
For max. no. of cables	2	No. of screw holes	2
Max. cable diameter	16 mm	Diam. of screw holes	5,8 mm
Length	73 mm	Screw material	Edelstahl V2A
Width	39 mm	Suitable for grommets	2 x KT small