

KT cable grommets, black

for cable diameters 1 - 35 mm / IP66 / IP68



Cable grommets KT small are used with the following cable entry components:

- KEL cable entry frames
- KVT split cable glands

In combination with KEL-ER cable entry frames and KVT-ER cable glands the KT single-hole grommets enable a sealing of the cables with up to IP66 / IP68.

The model range KT small is designed for cable diameters from 1 to 17 mm. Cable grommets KT large accept a wide range of cable diameters from 16 to 35 mm.

When installing the small grommets in multiple rows, the flat sides should be facing each other. This allows the flat sides to match up and provide a secure seal.

IP54

IP55

IP64

IP65

IP66

IP67

IP68



RIWA



ECOLAB certified



RoHS compliant



Made in Germany


Specifications


IP rating (EN 60529)	IP54, IP55, IP64, IP65, IP66, IP67, IP68
Material	Elastomer
Flame class	UL94-HB
Operating temperature	-30 C° to 90 C°
Properties	Higher chemical higher chemical resistance


Advantages & Benefits

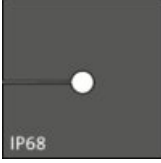
- Enable routing of pre-terminated cables through cable entry frames and split cable glands
- Available for a large range of cable diameters
- Greatly increased cable density when using double or quadruple grommets


Product types & Sizes


BTK bk 	Part No.	41351	Height	19 mm
	EAN	4251269307072	Mounting height	2 mm
	PU	10	For cable type	Rundleitung
	Color	schwarz	Blank grommet	1
	Length	21 mm		
	Width	21 mm		
	IP68			

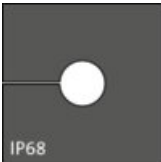
KT 1 bk 	Part No.	39943	Height	19 mm
	EAN	4251269318160	Mounting height	2 mm
	PU	10	For cable type	Rundleitung
	For max. no. of cables	1	Clamping range	1 x 1 - 2 mm
	Color	schwarz		
	Length	21 mm		
	Width	21 mm		
	IP68			


KT 2 bk 	Part No.	41302	Height	19 mm
	EAN	4251269306761	Mounting height	2 mm
	PU	10	For cable type	Rundleitung
	For max. no. of cables	1	Clamping range	1 x 2 - 3 mm
	Color	schwarz		
	Length	21 mm		
	Width	21 mm		

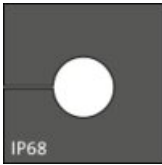
KT 3 bk 	Part No.	41303	Height	19 mm
	EAN	4251269306778	Mounting height	2 mm
	PU	10	For cable type	Rundleitung
	For max. no. of cables	1	Clamping range	1 x 3 - 4 mm
	Color	schwarz		
	Length	21 mm		
	Width	21 mm		

KT 4 bk 	Part No.	41304	Height	19 mm
	EAN	4251269306785	Mounting height	2 mm
	PU	10	For cable type	Rundleitung
	For max. no. of cables	1	Clamping range	1 x 4 - 5 mm
	Color	schwarz		
	Length	21 mm		
	Width	21 mm		

KT 5 bk 	Part No.	41305	Height	19 mm
	EAN	4251269306792	Mounting height	2 mm
	PU	10	For cable type	Rundleitung
	For max. no. of cables	1	Clamping range	1 x 5 - 6 mm
	Color	schwarz		
	Length	21 mm		
	Width	21 mm		

KT 6 bk 	Part No.	41306	Height	19 mm
	EAN	4251269306808	Mounting height	2 mm
	PU	10	For cable type	Rundleitung
	For max. no. of cables	1	Clamping range	1 x 6 - 7 mm
	Color	schwarz		
	Length	21 mm		
	Width	21 mm		

KT 7 bk 	Part No.	41307	Height	19 mm
	EAN	4251269306815	Mounting height	2 mm
	PU	10	For cable type	Rundleitung
	For max. no. of cables	1	Clamping range	1 x 7 - 8 mm
	Color	schwarz		
	Length	21 mm		
	Width	21 mm		

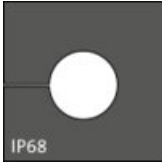
KT 8 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41308
4251269306822
10
1
schwarz
21 mm
21 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 8 - 9 mm

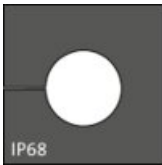
KT 9 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41309
4251269306839
10
1
schwarz
21 mm
21 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 9 - 10 mm

KT 10 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41310
4251269306846
10
1
schwarz
21 mm
21 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
x 10 - 11 mm

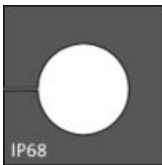
KT 11 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41311
4251269306853
10
1
schwarz
21 mm
21 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 11 - 12 mm

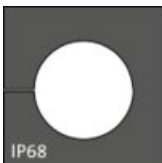
KT 12 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41312
4251269306860
10
1
schwarz
21 mm
21 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 12 - 13 mm

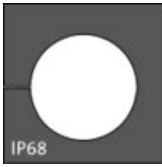
KT 13 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41313
4251269306877
10
1
schwarz
21 mm
21 mm

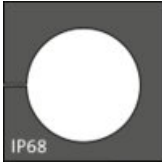
Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 13 - 14 mm

KT 14 bk

Part No. **41314**
 EAN **4251269306884**
 PU **10**
 For max. no. of cables **1**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **1 x 14 - 15 mm**

KT 15 bk

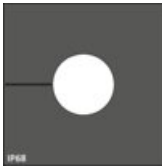
Part No. **41315**
 EAN **4251269306891**
 PU **10**
 For max. no. of cables **1**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **1 x 15 - 16 mm**

BTG bk (IP54)

Part No. **41352**
 EAN **4251269307089**
 PU **10**
 For max. no. of cables **1**
 Color **schwarz**
 Length **41,5 mm**
 Width **42 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Blank grommet **1**

KT 16 bk

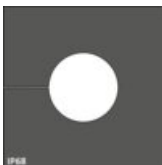
Part No. **41316**
 EAN **4251269306907**
 PU **10**
 For max. no. of cables **1**
 Color **schwarz**
 Length **41,5 mm**
 Width **42 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **1 x 16 - 17 mm**

KT 17 bk

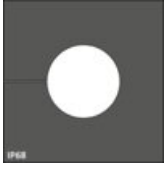
Part No. **41317**
 EAN **4251269306914**
 PU **10**
 For max. no. of cables **1**
 Color **schwarz**
 Length **41,5 mm**
 Width **42 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **1 x 17 - 18 mm**

KT 18 bk

Part No. **41318**
 EAN **4251269306921**
 PU **10**
 For max. no. of cables **1**
 Color **schwarz**
 Length **41,5 mm**
 Width **42 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **1 x 18 - 19 mm**

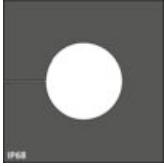
KT 19 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41319
4251269306938
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 19 - 20 mm

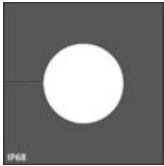
KT 20 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41320
4251269306945
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 20 - 21 mm

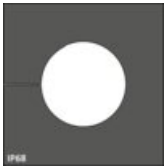
KT 21 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41321
4251269306952
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 21 - 22 mm

KT 22 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41322
4251269306969
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 22 - 23 mm

KT 23 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41323
4251269306976
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 23 - 24 mm

KT 24 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41324
4251269306983
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 24 - 25 mm

KT 25 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41325
4251269306990
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 25 - 26 mm

KT 26 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41326
4251269307003
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 26 - 27 mm

KT 27 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41327
4251269307010
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 27 - 28 mm

KT 28 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41328
4251269307027
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 28 - 29 mm

KT 29 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41329
4251269307034
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 29 - 30 mm

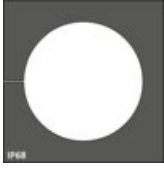
KT 30 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41330
4251269307041
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 30 - 31 mm

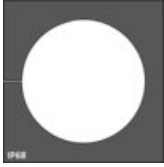
KT 31 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41331
4251269316807
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 31 - 32 mm

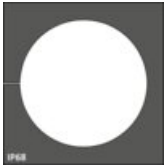
KT 32 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41332
4251269307058
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 32 - 33 mm

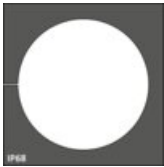
KT 33 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41333
4251269316814
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 33 - 34 mm

KT 34 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

41334
4251269307065
10
1
schwarz
41,5 mm
42 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 34 - 35 mm