

KT multi / special cable grommets, black

for cable diameters 1 - 8 mm and special cables / IP54



Cable grommets KT small are used with the following cable entry components:

- KEL cable entry frames
- KVT split cable glands

KT multi-hole and special grommets enable a sealing of the cables with IP54.

When using double or quadruple grommets the cable density of cable entry frames and cable glands can be greatly increased. The multi-hole model range KT small is designed for cable diameters from 1 to 8 mm. icotek also offers special cable grommets for e.g. ASI lines. ATG adapter grommets provide the possibility to hold a small KT grommet to reduce the clamping range down to 1 mm.

When installing the small grommets in multiple rows, the flat sides should be facing each other. This allows the flat sides to match up and provide a secure seal.

IP54



RIWA



ECOLAB certified



RoHS compliant



Made in Germany

Specifications

IP rating (EN 60529)	IP54
Material	Elastomer
Flame class	UL94-HB
Operating temperature	-30 C° to 90 C°
Properties	Higher chemical higher chemical resistance

Advantages & Benefits

- Enable routing of pre-terminated cables through cable entry frames and split cable glands
- Available for a large range of cable diameters
- Greatly increased cable density when using double or quadruple grommets

Product types & Sizes

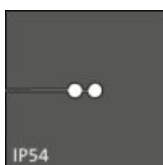
KT 2|1 bk



Part No.	39944
EAN	4251269318177
PU	10
For max. no. of cables	2
Color	schwarz
Length	21 mm
Width	21 mm

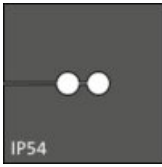
Height	19 mm
Mounting height	2 mm
For cable type	Rundleitung
Clamping range	2 x 1 - 1 mm

KT 2|2 bk



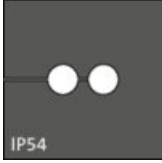
Part No.	39936
EAN	4251269306303
PU	10
For max. no. of cables	2
Color	schwarz
Length	21 mm
Width	21 mm

Height	19 mm
Mounting height	2 mm
For cable type	Rundleitung
Clamping range	2 x 2 - 2 mm

KT 2|3 bk

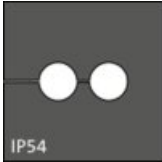
Part No. **39940**
 EAN **4251269306341**
 PU **10**
 For max. no. of cables **2**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **2 x 3 - 3 mm**

KT 2|4 bk

Part No. **39907**
 EAN **4251269306075**
 PU **10**
 For max. no. of cables **2**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **2 x 4 - 4 mm**

KT 2|5 bk

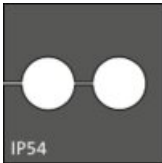
Part No. **39904**
 EAN **4251269306044**
 PU **10**
 For max. no. of cables **2**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **2 x 5 - 5 mm**

KT 2|6 bk

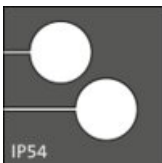
Part No. **39905**
 EAN **4251269306051**
 PU **10**
 For max. no. of cables **2**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **2 x 6 - 6 mm**

KT 2|7 bk

Part No. **39916**
 EAN **4251269306167**
 PU **10**
 For max. no. of cables **2**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **2 x 7 - 7 mm**

KT 2|8 bk

Part No. **39918**
 EAN **4251269306181**
 PU **10**
 For max. no. of cables **2**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **2 x 8 - 8 mm**

KT 4|2 bk

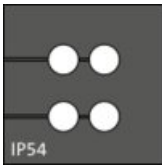
Part No. **39938**
 EAN **4251269306327**
 PU **10**
 For max. no. of cables **4**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **4 x 2 - 2 mm**

KT 4|3 bk

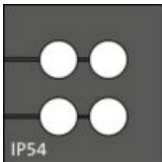
Part No. **39915**
 EAN **4251269306150**
 PU **10**
 For max. no. of cables **4**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **4 x 3 - 3 mm**

KT 4|4 bk

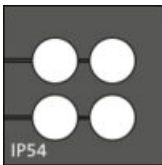
Part No. **39911**
 EAN **4251269306112**
 PU **10**
 For max. no. of cables **4**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **4 x 4 - 4 mm**

KT 4|5 bk

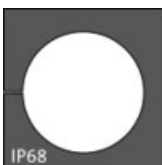
Part No. **39910**
 EAN **4251269306105**
 PU **10**
 For max. no. of cables **4**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **4 x 5 - 5 mm**

KT 4|6 bk

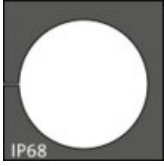
Part No. **39933**
 EAN **4251269306273**
 PU **10**
 For max. no. of cables **4**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **4 x 6 - 6 mm**

KTs 16 bk

Part No. **39912**
 EAN **4251269306129**
 PU **10**
 For max. no. of cables **1**
 Color **schwarz**
 Length **21 mm**
 Width **21 mm**

Height **19 mm**
 Mounting height **2 mm**
 For cable type **Rundleitung**
 Clamping range **1 x 16 - 16 mm**

KTs 17 bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

39913
4251269306136
10
1
schwarz
21 mm
21 mm

Height
Mounting height
For cable type
Clamping range

19 mm
2 mm
Rundleitung
1 x 17 - 17 mm

KT-ASI bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

39903
4251269306037
10
1
schwarz
21 mm
21 mm

Height
Mounting height
For cable type

19 mm
2 mm
ASI Leitung

KT-ASI-2 II bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

39923
4251269306211
10
2
schwarz
21 mm
21 mm

Height
Mounting height
For cable type

19 mm
2 mm
ASI Leitung

KT-ASI-2 rl bk

Part No.
EAN
PU
For max. no. of cables
Color
Length
Width

39924
4251269306228
10
2
schwarz
21 mm
21 mm

Height
Mounting height
For cable type

19 mm
2 mm
ASI Leitung

ATG bk

Part No.
EAN
PU
Color
Length
Width
Height

41353
4251269307096
10
schwarz
41,5 mm
42 mm
19 mm

Mounting height

2 mm