

Fork Terminals

Nylon Insulated Heavy Duty Double Crimp


TYPE ILSCONS

Features

- Fork tongue
- Barrel allows for two crimps
- Funnel wire entry
- Nylon insulation
- Color coded
- Manufactured from high strength copper alloy
- Electro-tin plated
- Brazed barrel
- UL Listed for 600 volts, 105° C

Benefits

- Allows easy installation since mounting screw needs only to be loosened
- Provides strain relief, prevents exposure of wire conductors
- Smooth wire insertion into barrel
- Increased heat and chemical resistant qualities for more demanding applications
- Provide easy wire range identification
 - #18-22 AWG Red
 - #14-16 AWG Blue
 - #10-12 AWG Yellow
- Offers maximum conductivity
- Provides low contact resistance
- Stronger crimp connection that will not split open, prevents wire pull out
- Ensures reliability for copper conductor

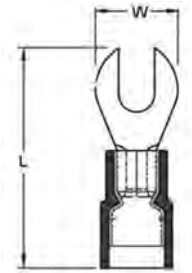

Catalog Number	Wire Range	Stud Size	Dimensions - in. (mm)				Installation Tool ILST-22K	Package Quantity
			L		W			
NFBRD-18-6-P50	18-22	6	0.768	(19.5)	0.260	(6.6)	Die Set B	50
NFBRD-18-14-P50	18-22	1/4	1.035	(26.3)	0.457	(11.6)	Die Set B	50
NFBRD-14-8-P50	14-16	8	0.862	(21.9)	0.335	(8.5)	Die Set B	50
NFBRD-14-14-P50	14-16	1/4	1.047	(26.6)	0.472	(12.0)	Die Set B	50
NFBRD-10-8-P25	10-12	8	0.839	(21.3)	0.283	(7.2)	Die Set B	25
NFBRD-10-10-P25	10-12	10	1.008	(25.6)	0.374	(9.5)	Die Set B	25
NFBRD-10-14-P25	10-12	1/4	1.110	(28.2)	0.472	(12.0)	Die Set B	25

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)

Tested to UL 486A/B, UL File E6207