


TYPE  
**GPL3**

**Features**

- Range taking
- Cable clamp rotates
- Silicon bronze hardware
- UL 467 Listed

**Benefits**

- Inventory reduction
- Allows ground conductor to be attached parallel to pipe or at 90°
- Corrosion resistant
- Suitable for direct burial in earth or concrete

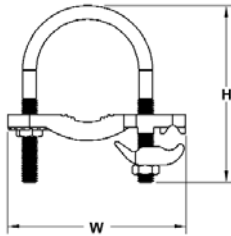

Catalog Number	Ground Wire Range	IPS Pipe Size	Dimensions		Fits Pipe O.D. Range
			W	H	
GPL3902BU	4 - 4/0	1/2 - 1	3.250	3.500	.840 - 1.32
GPL3903BU	4 - 4/0	1-1/4 - 2	4.250	4.000	1.66 - 2.38
GPL3904BU	4 - 4/0	2-1/2 - 3-1/2	5.000	6.500	2.88 - 4.00
GPL3905BU	4 - 4/0	4 - 5	7.500	7.500	4.50 - 5.56
GPL3906BU	4 - 4/0	6	8.625	8.500	6.62
GPL3907BU	4 - 4/0	8	10.625	10.000	8.62
GPL3908BU	4 - 4/0	10	12.750	12.000	10.75
GPL3909BU	4 - 4/0	12	14.750	14.000	12.75

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)  
UL File E34440