




TYPE T

Features

- Manufactured from pure copper braid
- Electro-tin plated
- Seamless pure copper ferrules
- Inside ferrule ends are rounded
- Ferrule ends swedged to braid
- Extra flexible braid

Benefits

- Provides superior ground path
- Corrosion resistant
- Low resistance
- Prevent chafing of strands
- Permanent low-resistance connection
- Easily connects and bonds moving parts

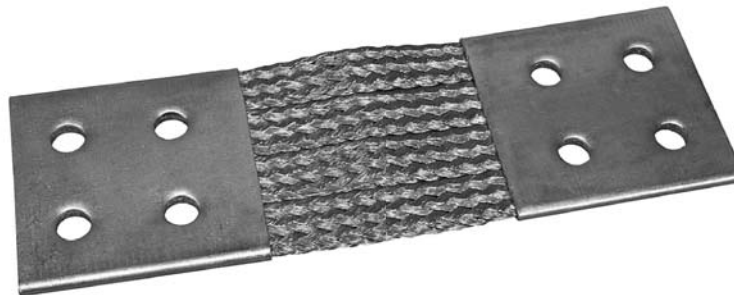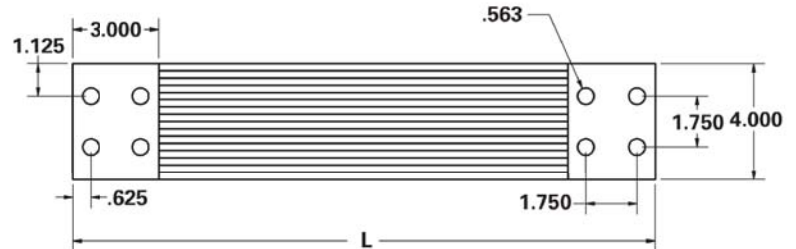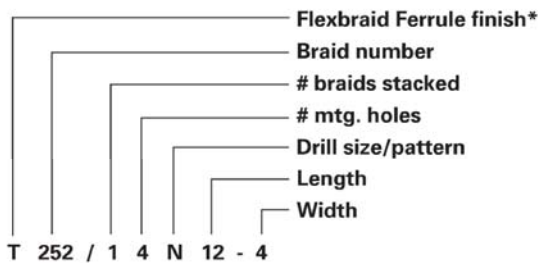

Catalog Number*	Number of Mounting Holes	Mounting Hole Diameter	Amps	Circular Mils. of Braids	Number of stacked braids	Dimensions		
						L**	T	W
T278/14N12-4	4	0.562	625	422	1	12.000	0.250	4.000
T278/24N12-4	4	0.562	940	844,000	2	12.000	0.310	4.000
T278/34N12-4	4	0.562	1200	1,266,000	3	12.000	0.380	4.000
T278/44N12-4	4	0.562	1600	1,688,000	4	12.000	0.500	4.000

* Add suffix "T" for tin-plated

** The two digits following the letter "N" define overall length in inches (12 equals 12:- shown). For length other than 12 inches, insert the desired length.