

ILSCO Cast Bronze Ground Rod Clamps

RoHS
Compliant

UL
LISTED
667P

SA
LR-29601


TYPE BGRC

Features

- Manufactured from cast bronze
- Supplied with stainless steel or silicone bronze hardware
- Copper conductor only

Benefits

- Ensures maximum strength and durability
- Suitable for direct burial in earth or concrete

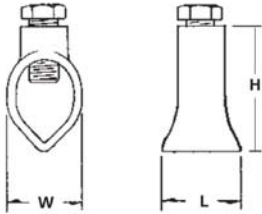

C

Catalog Number	Ground Rod Size	Rebar Size	Ground Rod Wire Range	Rebar Wire Range	Dimensions		
					L	W	H
BGRC-48	1/2	-	2-10	-	7/8	3/4	1-1/4
BGRC-58	5/8	#5	1/0-8	1/0-8	1-1/32	29/32	1-13/32
BGRC-68	3/4	-	1/0-8	-	1	1	1-5/8

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)
Tested to UL 467, UL File E34440

