


TYPE CL

Features

- Range taking
- Easily installed with a key wrench
- Convenient peep hole
- Re-usable
- Suitable for use in circuits rated 35KV or less, proper high voltage spacing and insulation techniques must be used
- Rated for 90° C

Benefits

- Permits inventories to be kept to a minimum
- Time savings
- Easy inspection
- Provides efficient use and flexibility in the field
- Application versatility

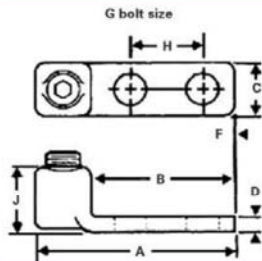

Catalog Number	Wire Range	Dimensions							
		G	A	B	C	D	J	F	H
CL-1-2/0N	2/0-1	1/2	3-15/16	3	1	1/4	11/16	9/16	1-3/4
CL-1-4/0N	4/0-2/0	1/2	4-1/8	3	1	9/32	1-9/32	9/16	1-3/4
CL-1-300N	300kcmil-4/0	1/2	4-3/16	3	1-3/16	5/16	1-15/32	9/16	1-3/4
CL-1-500N	500kcmil-300kcmil	1/2	4-7/8	3-1/2	1-3/8	11/32	1-13/16	9/16	1-3/4
CL-1-750N	750kcmil-500kcmil	1/2	5-3/32	3-1/2	1-3/4	13/32	2-1/8	9/16	1-3/4
CL-1-1000N	1000kcmil-750kcmil	1/2	5-1/4	3-1/2	3	15/32	2-1/8	9/16	1-3/4

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)
Furnished with bolt holes and spacing to fit equipment supplied with NEMA type connector mounting pads.
UL File E158587