

TYPE N



Features

- Manufactured from electrolytic copper tubing and strip stock
- Compact design
- Range taking
- Re-usable
- V-bottom collar
- Suitable for use in circuits rated 35KV or less, proper high voltage spacing and insulation techniques must be used
- Rated for 90° C

Benefits

- Provides maximum conductivity and strength
- Saves space and reduces installation time
- Permits inventories to be kept to a minimum
- Provides efficient use and flexibility in the field
- Wires are wedged between arched pressure bar and collar establishing positive contact and firm permanent grip
- Application versatility

C

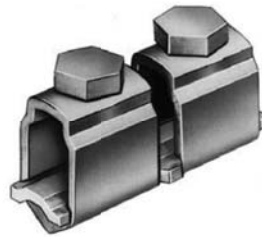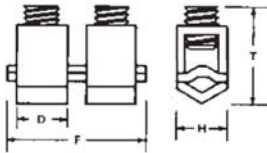

| Catalog Number | Wire Range | Dimensions | | | | Hex Size |
|----------------|-----------------------------|------------|--------|-----|---------|----------|
| | | D | F | H | T | |
| N-25 | 10-14 | 9/32 | 13/16 | 1-4 | 19/32 | Slot |
| N-35 | 6-14 & List Combination (A) | 7/16 | 1-3/16 | 3/8 | 11/16 | Slot |
| N-70 | 2-8 & List Combination (B) | 1/2 | 1-3/8 | 1/2 | 31/32 | Slot |
| N-225 | 4/0-2 | 1 | 2-9/16 | 1 | 1-21/32 | 7/32 |

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG)

(A) UL Listed wire combinations: (2) #10; (2) #12; (2) #14; (1) #12 and (1) #14; (1) #10 and (1) #12

(B) UL Listed wire combinations: (1) #8 and (1) #4; (1) #8 and (1) #6; (2) #4; (3) #8; (3) #6; (2) #8 and (1) #4; (2) #8 and (1) #6; (1) #6 and (1) #4; (2) #6

Tested to UL 486A/B, UL File E6207